




Fiber optic diffuse reflection sensor

FT-00-A-A-M6/S 1,3m lang

Article no longer available - archive entry

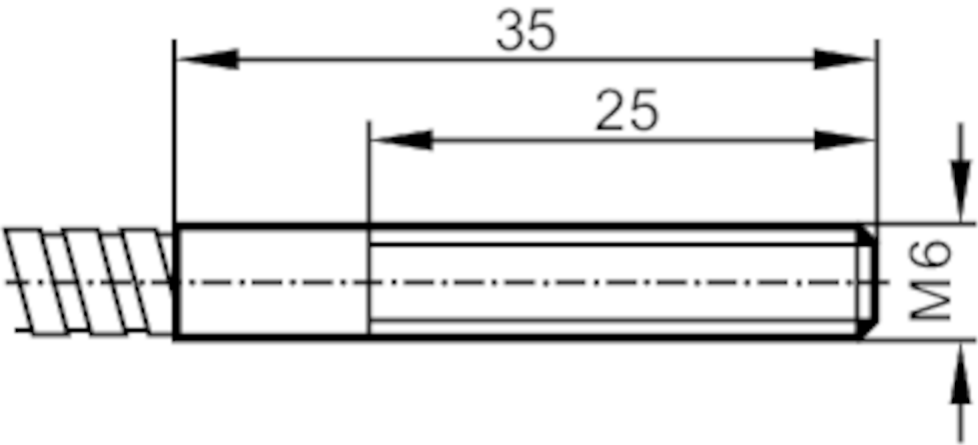

| Application                           |                           |
|---------------------------------------|---------------------------|
| Function principle                    | Diffuse reflection sensor |
| Monitoring range                      |                           |
| Range with fiber optic amplifier type | OKF; OUF                  |
| OKF                                   |                           |
| Range fiber optics [mm]               | 40                        |
| OUF                                   |                           |
| Range fiber optics [mm]               | 40                        |
| Operating conditions                  |                           |
| Ambient temperature [°C]              | -40...350                 |
| Mechanical data                       |                           |
| Version of sensing head               | straight                  |
| Sensing head thread                   | M6                        |
| Sensing head length [mm]              | 35                        |
| Total length [mm]                     | 1300                      |
| Min. bending radius [mm]              | 20                        |
| Material                              | Adapter: ABS              |
| Fiber material                        | glass                     |

E20264



Fiber optic diffuse reflection sensor

FT-00-A-A-M6/S 1,3m lang

|                       |          |
|-----------------------|----------|
| Fiber head material   | aluminum |
| Fiber sheath material | aluminum |
| Remarks               |          |
| Pack quantity         | 1 pcs.   |