




Fiber optic diffuse reflection sensor

FT-00-R3

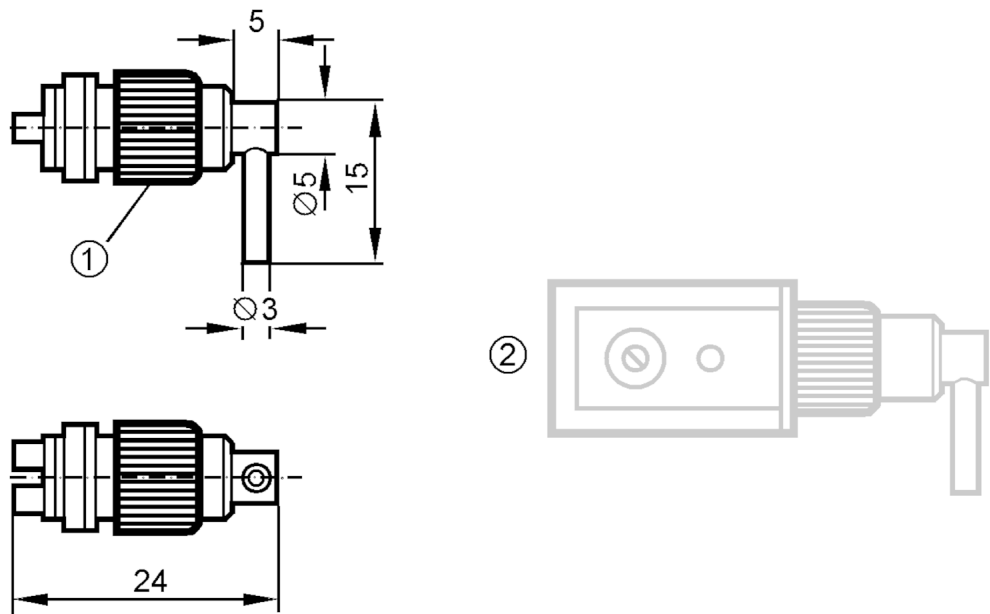

- 1 knurled nut
- 2 OKFF with fiber optic

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF
OKF	
Range fiber optics [mm]	25
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Weight [g]	14
Version of sensing head	angled; with adapter for direct mounting
Sensing head diameter [mm]	3
Total length [mm]	24
Fiber arrangement	⓪
Material	knurled nut: plastics
Fiber material	glass
Fiber head material	stainless steel (1.4305 / 303)
Remarks	
Pack quantity	1 pcs.