




Fiber optic diffuse reflection sensor

FT-30-A-A-E6/3M

Article no longer available - archive entry

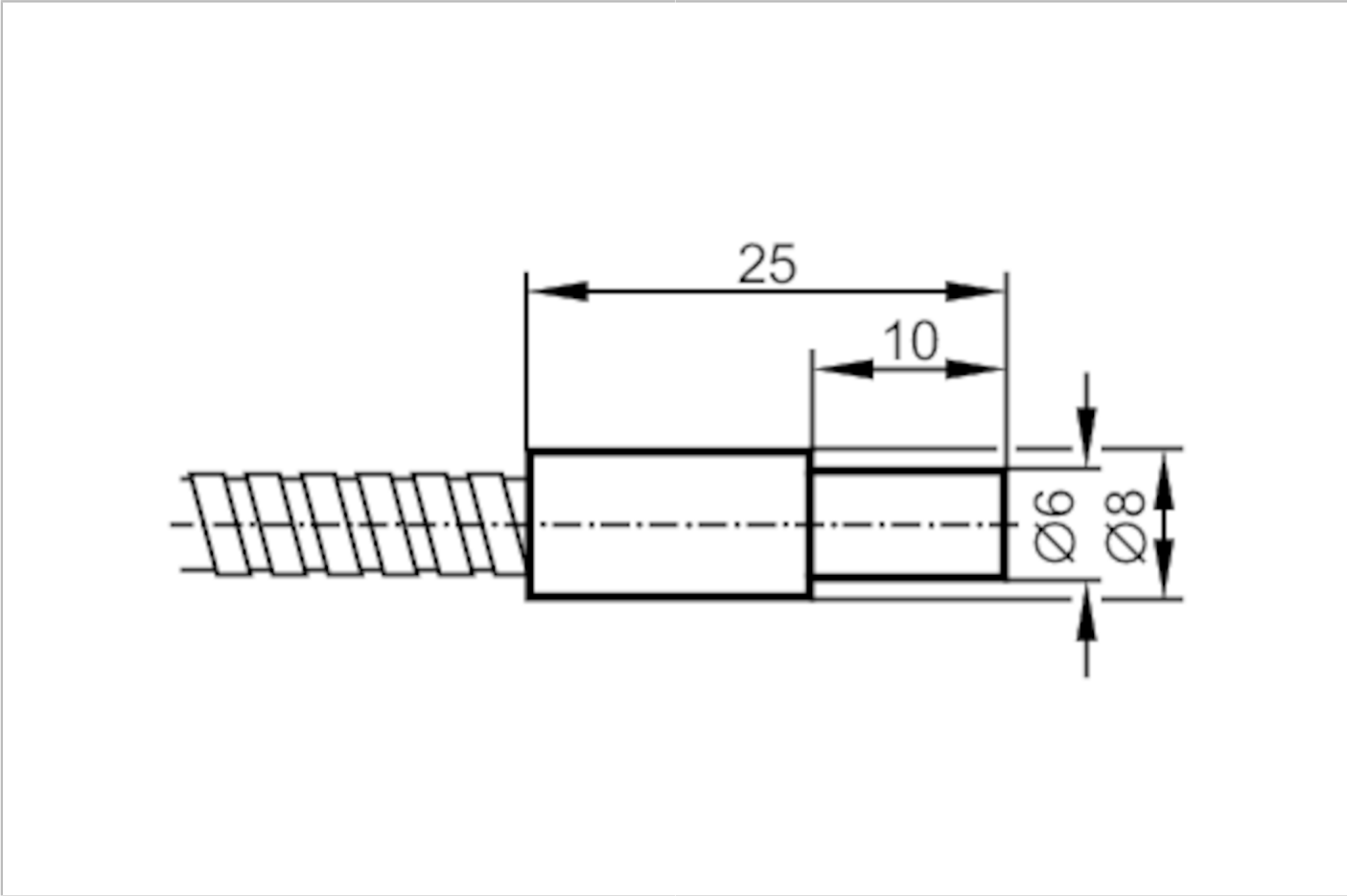

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	27
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	6
Total length [mm]	3000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	aluminum

E20272



Fiber optic diffuse reflection sensor

FT-30-A-A-E6/3M

Accessories	
Items supplied	Mounting clamp:, E10221
Remarks	
Pack quantity	1 pcs.