




Fiber optic through beam sensor

FE-30-P-A-E3/2,5M

Article no longer available - archive entry

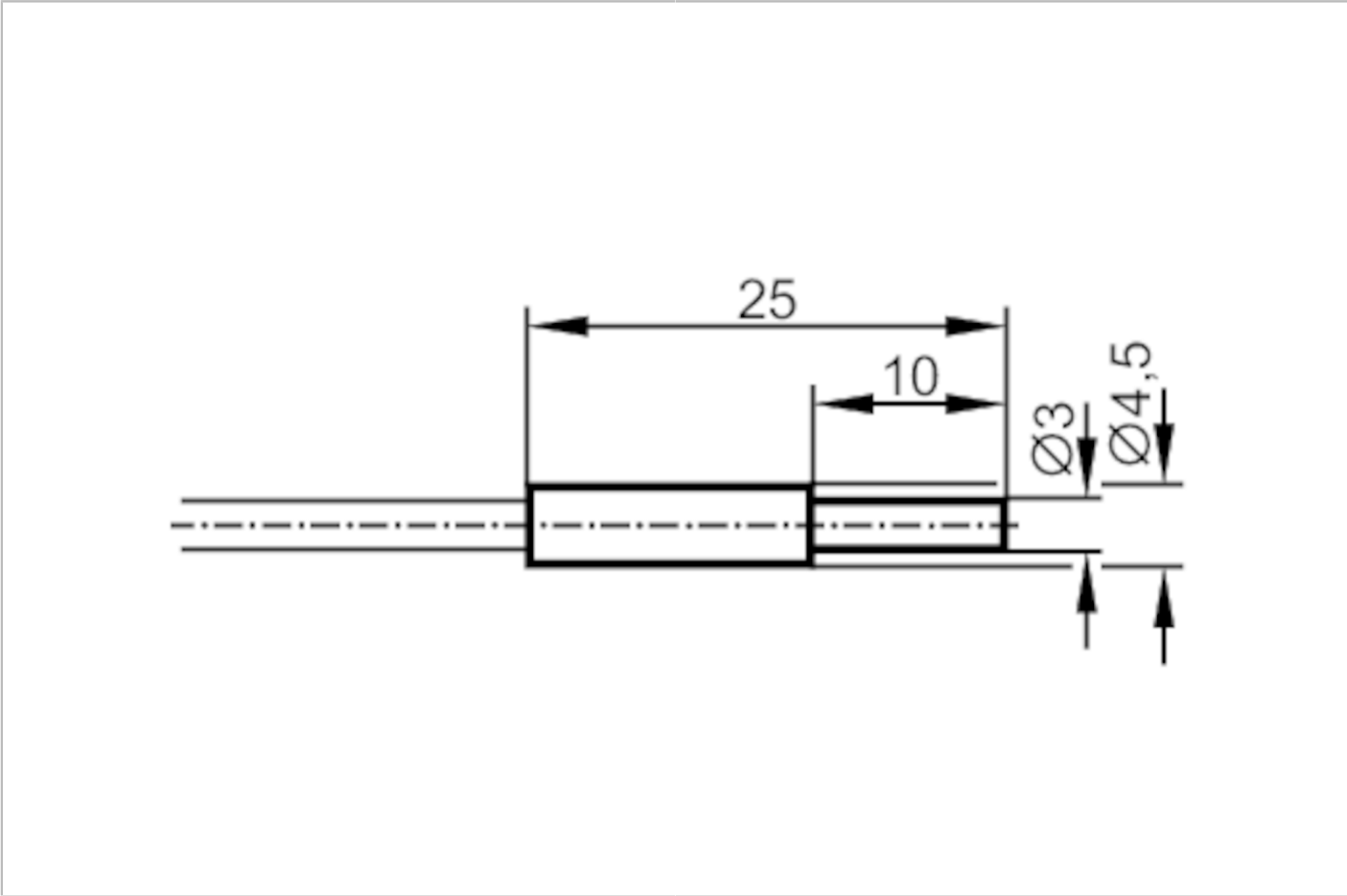

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range of fiber optics [mm]	70
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Total length [mm]	2500
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC

E20295



Fiber optic through beam sensor

FE-30-P-A-E3/2,5M

Remarks	
---------	--

Pack quantity	1 pcs.
---------------	--------