




Fiber optic through beam sensor

FE-30-A-A-M6/4M

Article no longer available - archive entry

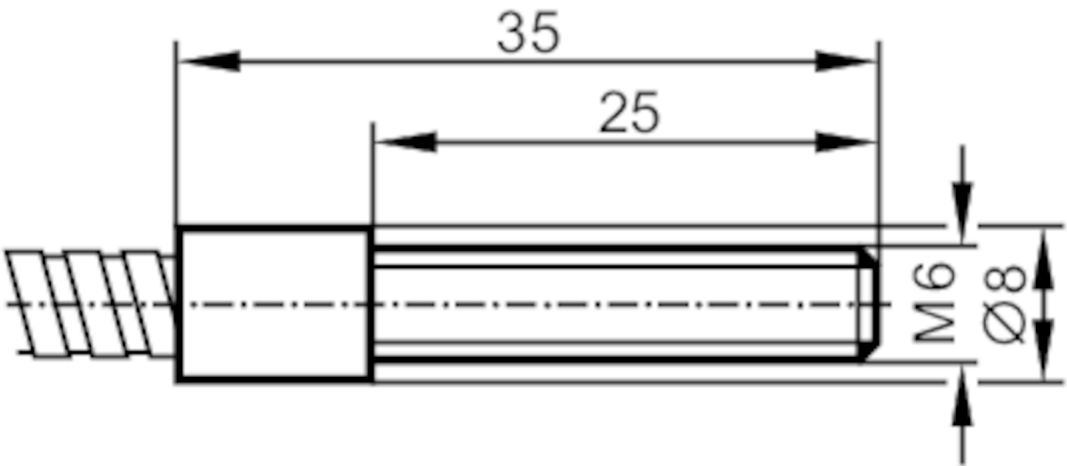

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range of fiber optics [mm]	154
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head thread	M6
Total length [mm]	4000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	aluminum

E20308



Fiber optic through beam sensor

FE-30-A-A-M6/4M

Remarks

Pack quantity	1 pcs.
---------------	--------