




Fiber optic through beam sensor

FE-30-A-A-R3/1.5M

Article no longer available - archive entry

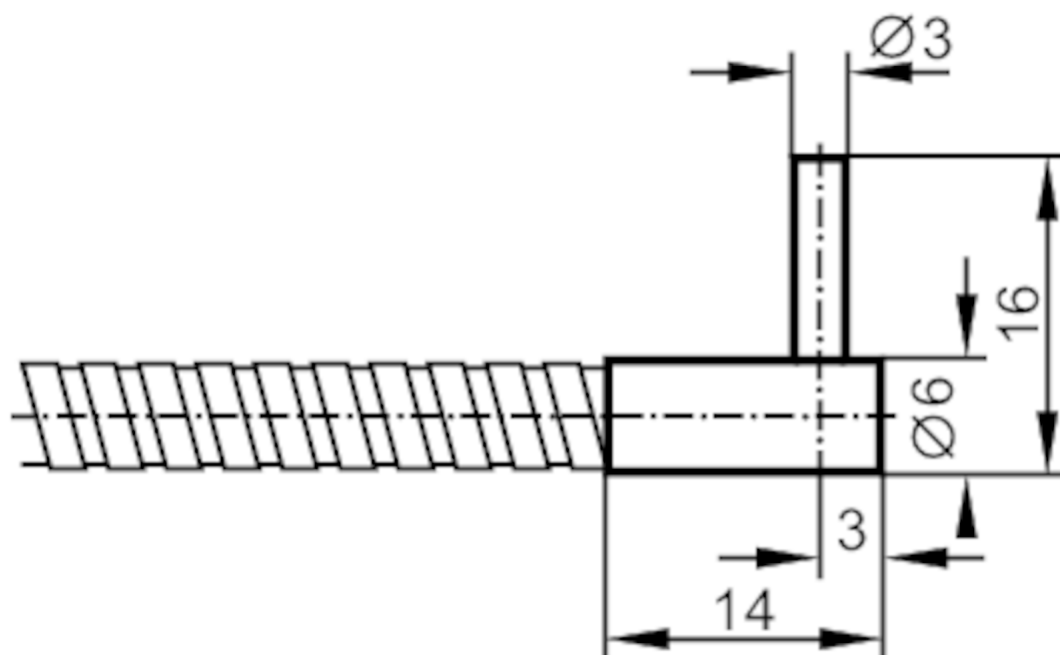

Application

Function principle

Through-beam sensor

Monitoring range

Range with fiber optic
amplifier type

OIF

OIF

Range of fiber optics

[mm]

90

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Total length

[mm]

1500

Min. bending radius

[mm]

30

Fiber arrangement



Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

aluminum

E20309



Fiber optic through beam sensor

FE-30-A-A-R3/1.5M

Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.