

E20312




Fiber optic diffuse reflection sensor

FT-30-P-A-M8/3M

Article no longer available - archive entry

Alternative articles: E20313
When selecting an alternative article and accessories please note that technical data may differ!

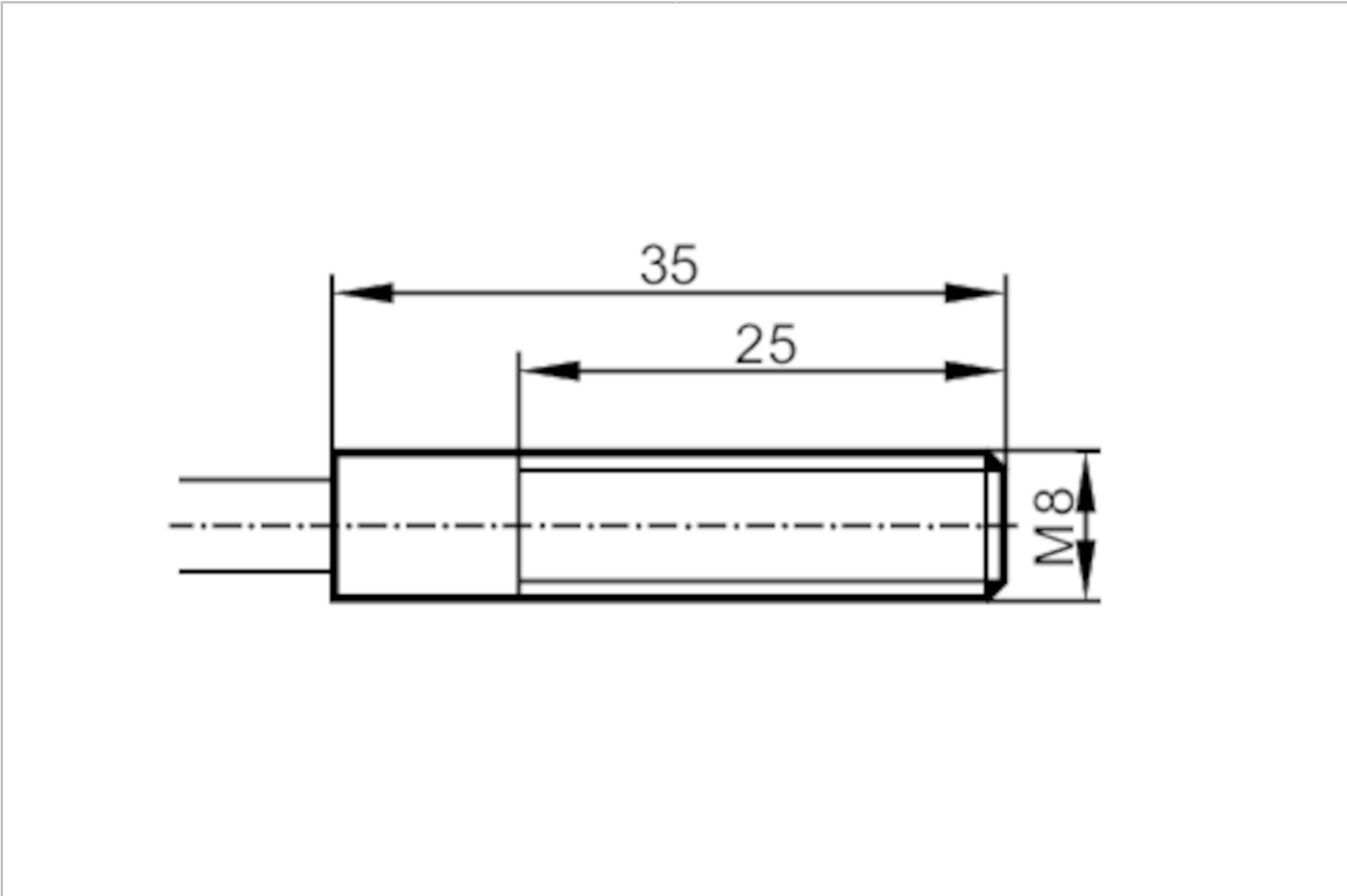

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	45
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	3000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum

E20312



Fiber optic diffuse reflection sensor

FT-30-P-A-M8/3M

Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.