




Fiber optic diffuse reflection sensor

FT-30-P-A-E6/2m

Article no longer available - archive entry

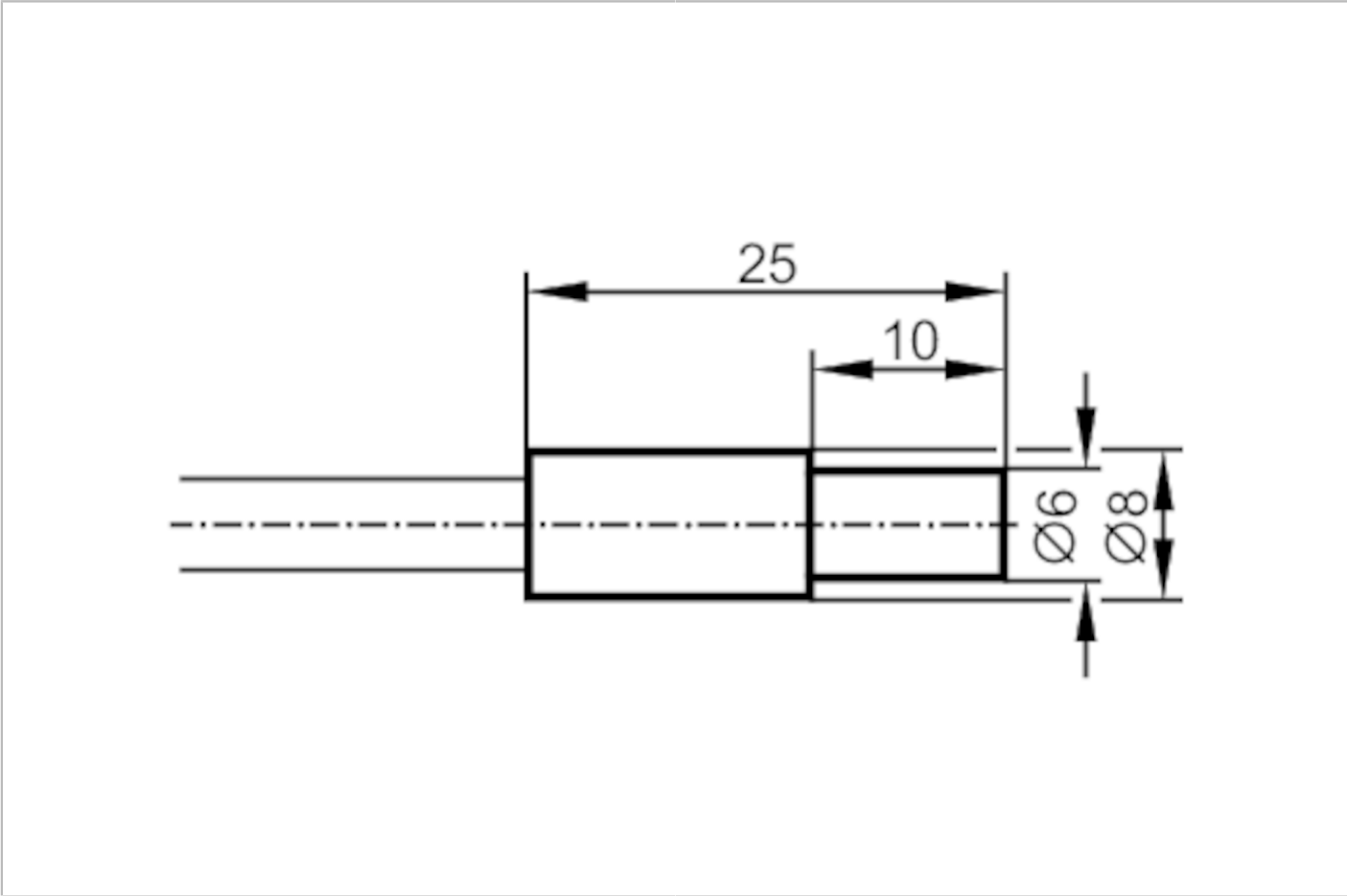

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range fiber optics [mm]	32
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	6
Total length [mm]	2000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC

E20316



Fiber optic diffuse reflection sensor

FT-30-P-A-E6/2m

Remarks	
---------	--

Pack quantity	1 pcs.
---------------	--------