




## Fiber optic diffuse reflection sensor

FT-30-P-A-R6/3m

Article no longer available - archive entry

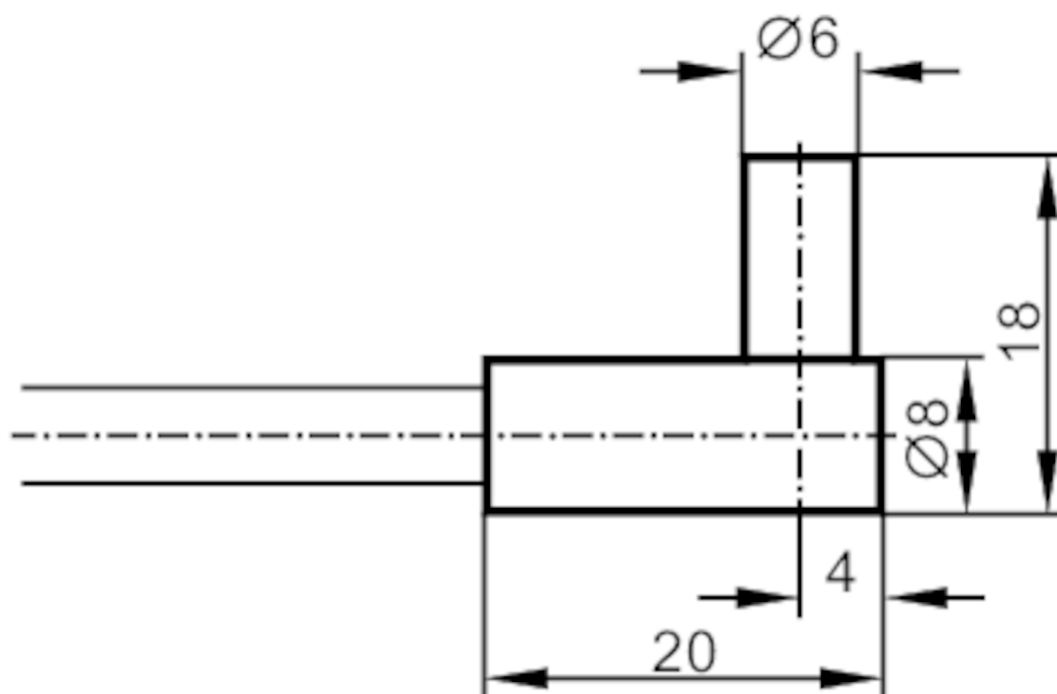

## Application

Function principle

Diffuse reflection sensor

## Monitoring range

Range with fiber optic amplifier type

OIF

OIF

Range fiber optics

[mm]

26

## Operating conditions

Ambient temperature

[°C]

-20...80

## Mechanical data

Version of sensing head

angled

Total length

[mm]

3000

Min. bending radius

[mm]

30

Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

PVC

## Remarks

Pack quantity

1 pcs.