




## Fiber optic through beam sensor

FE-30-P-A-R6/2m

Article no longer available - archive entry

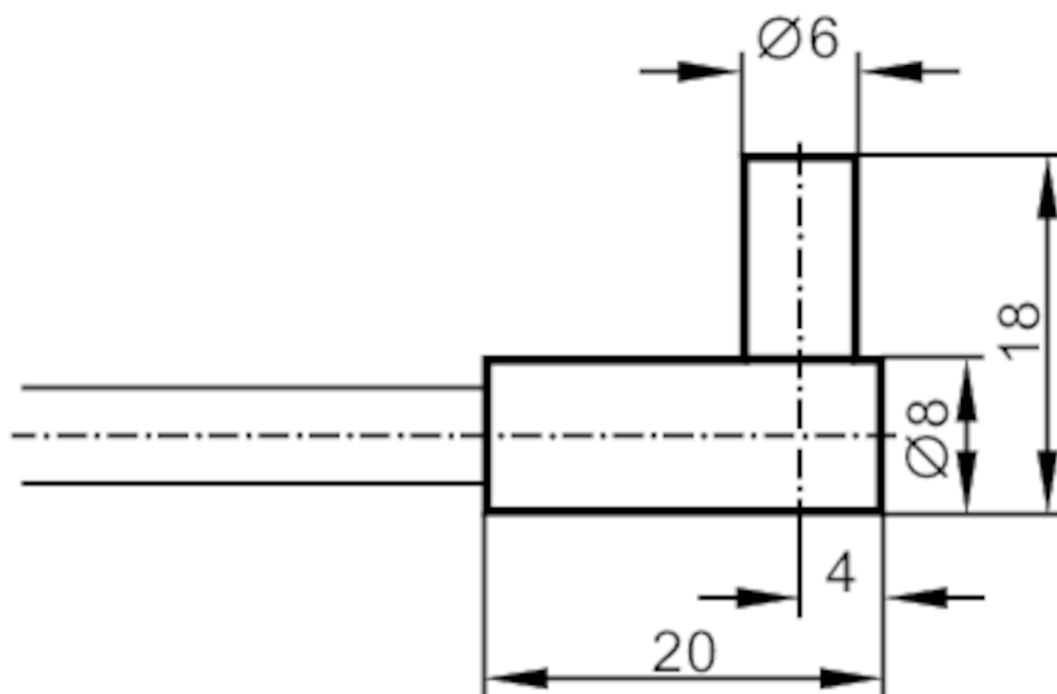

## Application

Function principle

Through-beam sensor

## Monitoring range

Range with fiber optic amplifier type

OIF

OIF

Range of fiber optics

[mm]

240

## Operating conditions

Ambient temperature

[°C]

-20...80

## Mechanical data

Version of sensing head

angled

Total length

[mm]

2000

Min. bending radius

[mm]

30

Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

PVC

## Remarks

Pack quantity

1 pcs.