




Fiber optic through beam sensor

FE-30-P-A-R3/3m

Article no longer available - archive entry

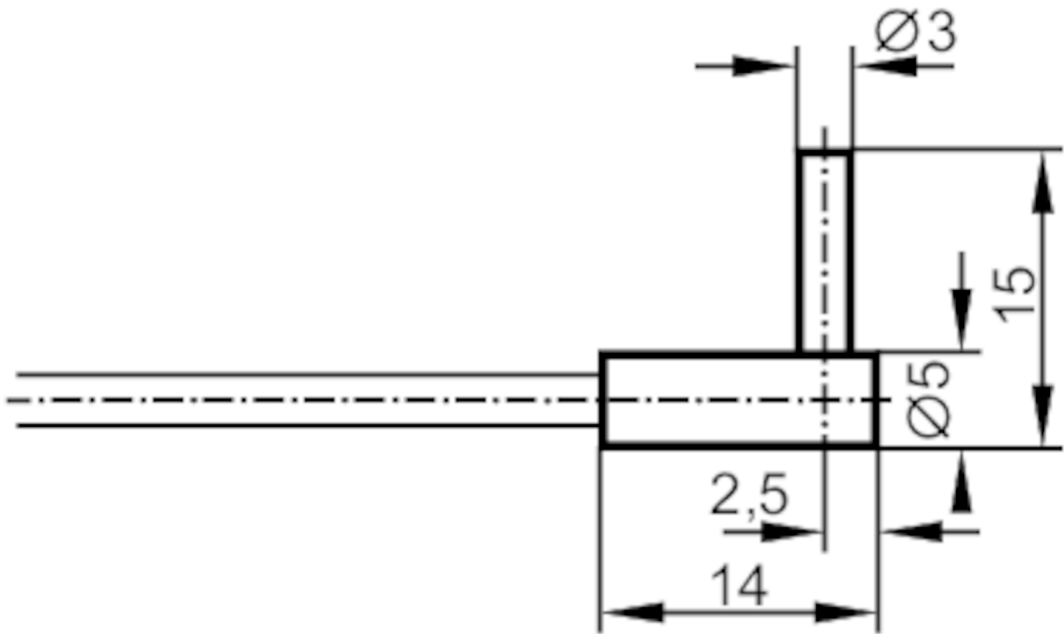

Application	
Function principle	Through-beam sensor
Monitoring range	
Range with fiber optic amplifier type	OIF
OIF	
Range of fiber optics [mm]	64
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	angled
Total length [mm]	3000
Min. bending radius [mm]	30
Material	Adapter: PA
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.