


Fiber optic through beam sensor

FE-30-P-A-E3/4m

Article no longer available - archive entry

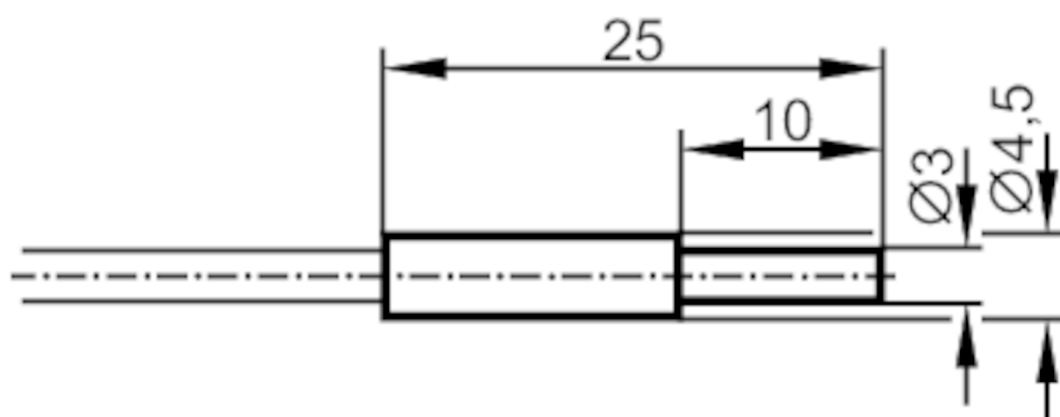

Application

Function principle

Through-beam sensor

Monitoring range

Range with fiber optic amplifier type

OIF

OIF

Range of fiber optics

[mm]

51

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Total length

[mm]

4000

Min. bending radius

[mm]

30

Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

PVC

E20338



Fiber optic through beam sensor

FE-30-P-A-E3/4m

Remarks	
Pack quantity	1 pcs.