




Fiber optic through beam sensor

FE-30-A-A-R3/4m

Article no longer available - archive entry

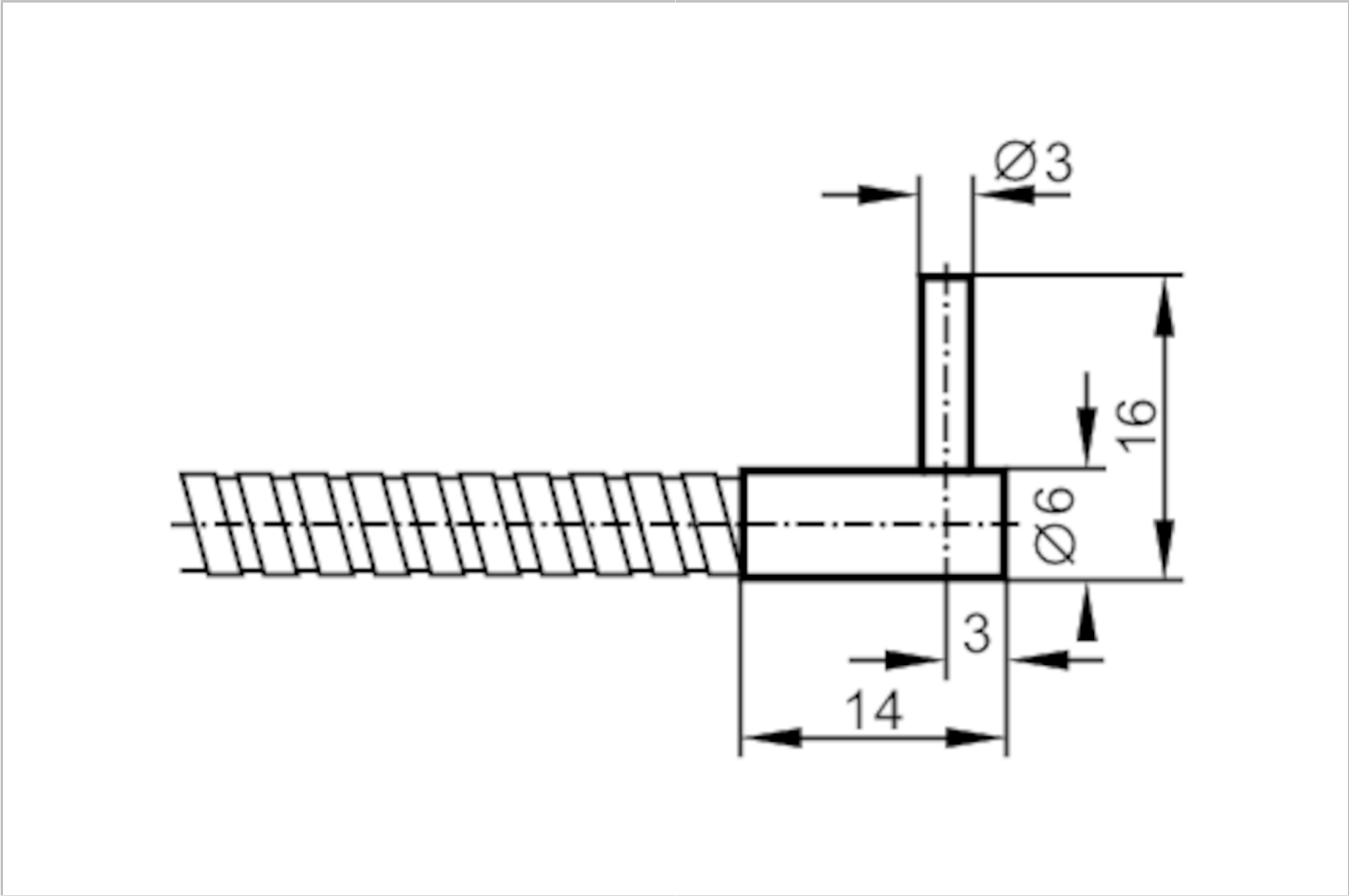

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OIF
OIF		
Range of fiber optics	[mm]	51
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Version of sensing head		angled
Total length	[mm]	4000
Min. bending radius	[mm]	30
Material		Adapter: PA
Fiber material		glass
Fiber head material		aluminum
Fiber sheath material		aluminum
Remarks		
Pack quantity		1 pcs.