


E20350



Fiber optic diffuse reflection sensor

FT-00-P-A-M6/2,5M

Article no longer available - archive entry

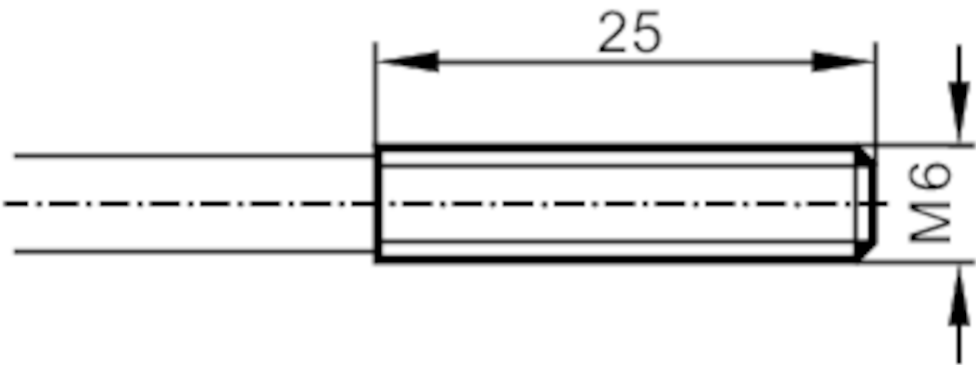

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range fiber optics	[mm]	28
OUF		
Range fiber optics	[mm]	28
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head thread		M6
Sensing head length	[mm]	25
Total length	[mm]	2500
Min. bending radius	[mm]	20
Material		Adapter: PPE
Fiber material		glass

E20350



Fiber optic diffuse reflection sensor

FT-00-P-A-M6/2,5M

Fiber head material	aluminum
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.