




Fiber optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

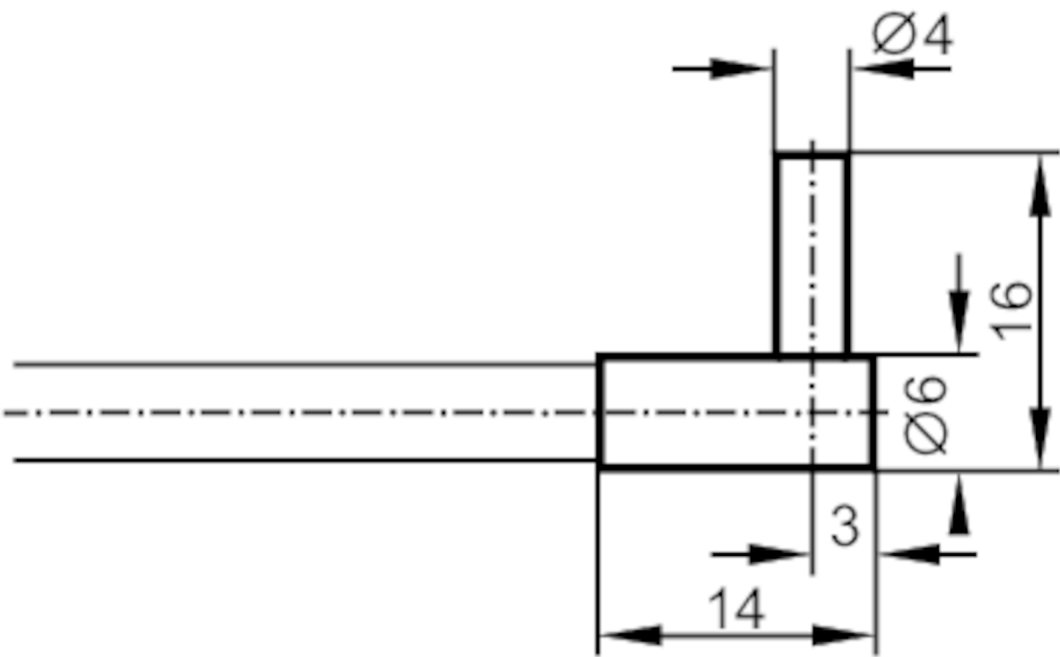

Application		
Function principle		Diffuse reflection sensor
Application		For use in industrial environments
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range fiber optics	[mm]	36
OUF		
Range fiber optics	[mm]	36
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	68.5
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	1500
Min. bending radius	[mm]	20
Fiber arrangement		Ⓢ

E20351



Fiber optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

Material	Adapter: PPE
Fiber material	glass
Fiber head material	aluminum
Fiber sheath material	PVC
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.