




Fiber optic diffuse reflection sensor

FT-00-P-A-E3/2,5M

Article no longer available - archive entry

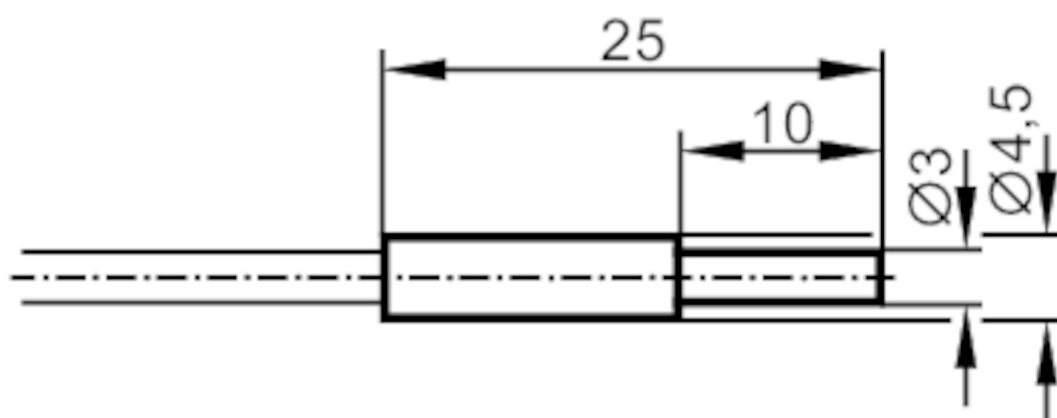

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic amplifier type

OKF; OUF

OKF

Range fiber optics

[mm]

28

OUF

Range fiber optics

[mm]

28

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

25

Total length

[mm]

2500

Min. bending radius

[mm]

20

Material

Adapter: PPE

Fiber material

glass

E20354



Fiber optic diffuse reflection sensor

FT-00-P-A-E3/2,5M

Fiber head material	aluminum
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.