




Fiber optic through beam sensor

FE-00-P-V-E1/2,5m

Article no longer available - archive entry

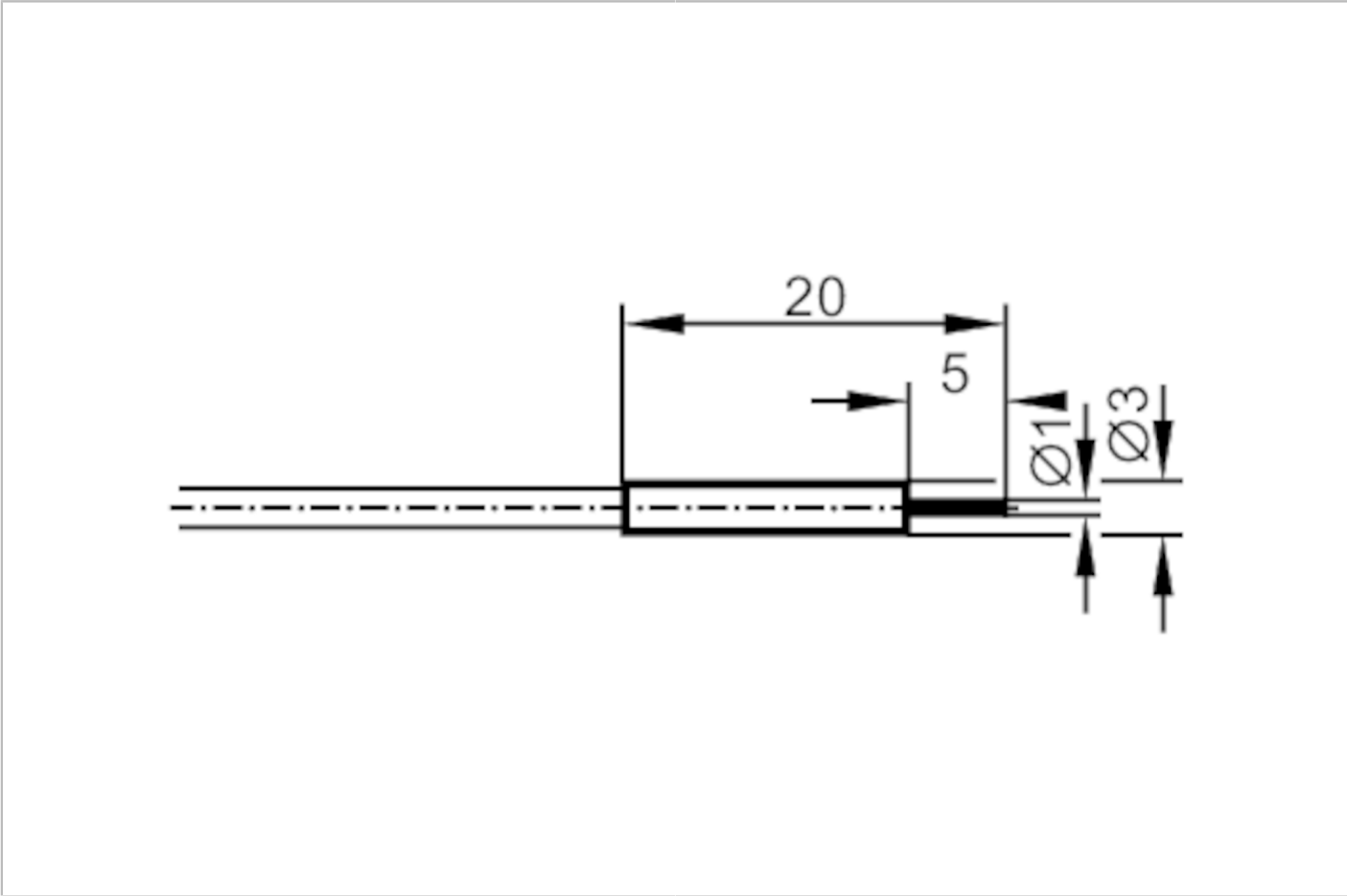

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range of fiber optics	[mm]	36
OUF		
Range of fiber optics	[mm]	36
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	1
Sensing head length	[mm]	5
Total length	[mm]	2500
Min. bending radius	[mm]	10
Material		Adapter: PPE
Fiber material		glass

E20360



Fiber optic through beam sensor

FE-00-P-V-E1/2,5m

Fiber head material	stainless steel (1.4305 / 303)
Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.