

E20373




Fiber optic diffuse reflection sensor

FT-00-P-V-E1/0,4M

Article no longer available - archive entry

Alternative articles: E20077
When selecting an alternative article and accessories please note that technical data may differ!

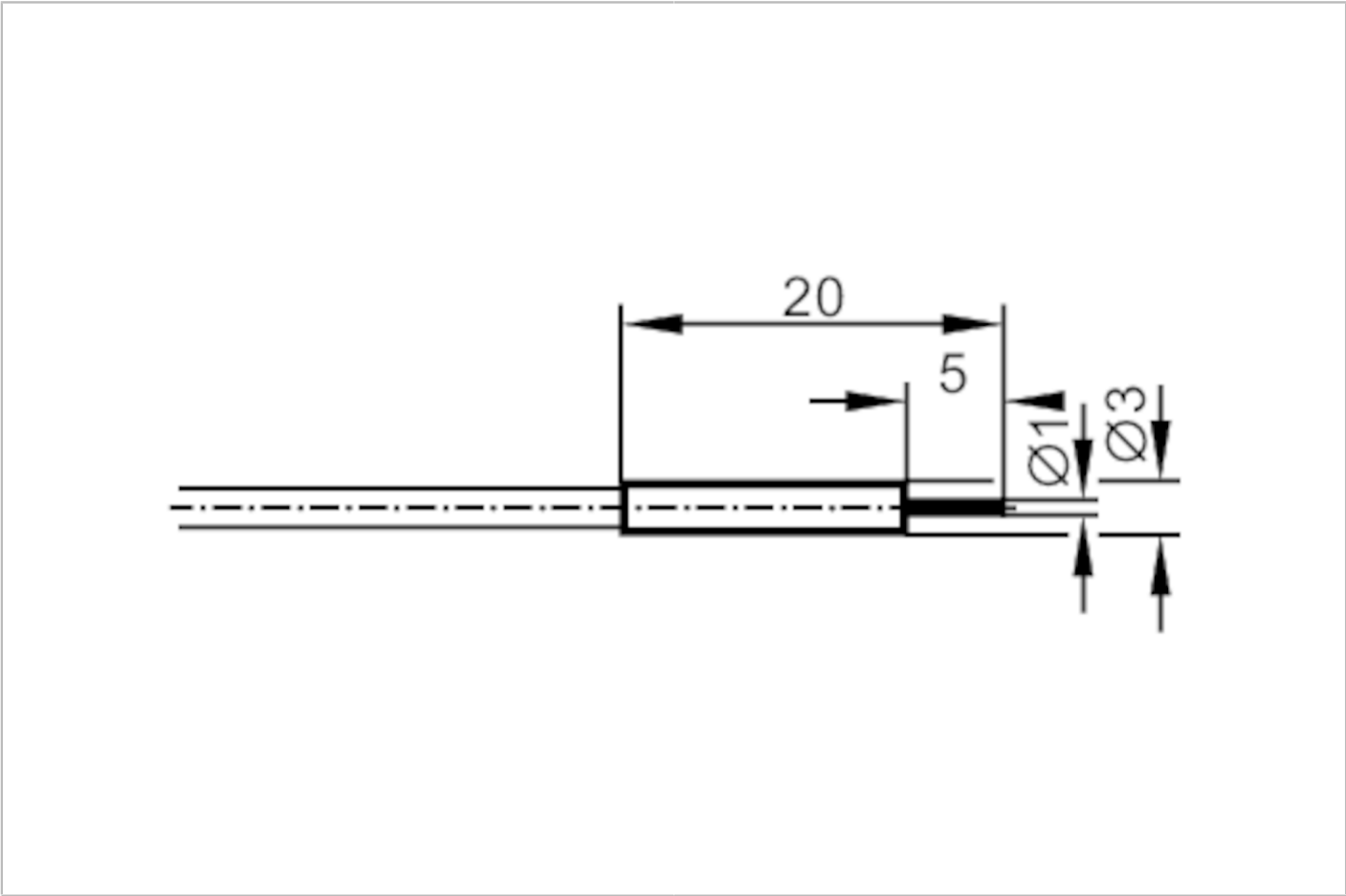

Application	
Function principle	Diffuse reflection sensor
Monitoring range	
Range with fiber optic amplifier type	OKF; OUF
OKF	
Range fiber optics [mm]	8
OUF	
Range fiber optics [mm]	8
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	400

E20373



Fiber optic diffuse reflection sensor

FT-00-P-V-E1/0,4M

Min. bending radius	[mm]	10
Material	Adapter: PPE	
Fiber material	glass	
Fiber head material	stainless steel (1.4305 / 303)	
Fiber sheath material	PVC	
Accessories		
Items supplied	Mounting clamp:, E20107	
Remarks		
Pack quantity	1 pcs.	