




Fiber optic diffuse reflection sensor

FT-18-A-A-M6

Article no longer available - archive entry

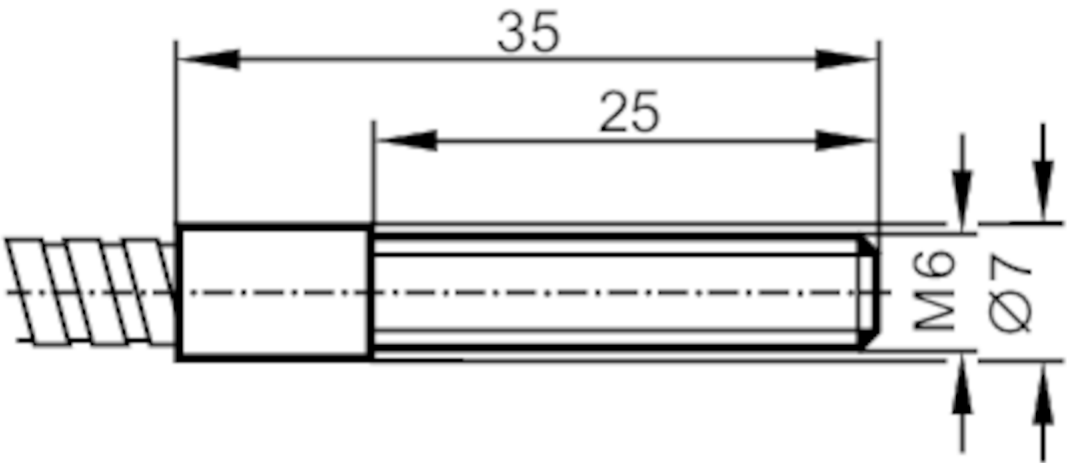

Application		
Function principle		Diffuse reflection sensor
Monitoring range		
Range with fiber optic amplifier type		OGF
OGF		
Range fiber optics	[mm]	15
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	0.055
Version of sensing head		straight
Sensing head thread		M6
Sensing head length	[mm]	25
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fiber arrangement		⓪
Material		Adapter: PPE
Fiber material		glass

E20385



Fiber optic diffuse reflection sensor

FT-18-A-A-M6

Fiber head material	aluminum
Fiber sheath material	aluminum
Accessories	
Items supplied	Hexagon nuts: 2 x M6, stainless steel
	tooth lock washers: 2
Remarks	
Pack quantity	1 pcs.