




Fiber optic through beam sensor

FE-18-A-A-R4

Article no longer available - archive entry

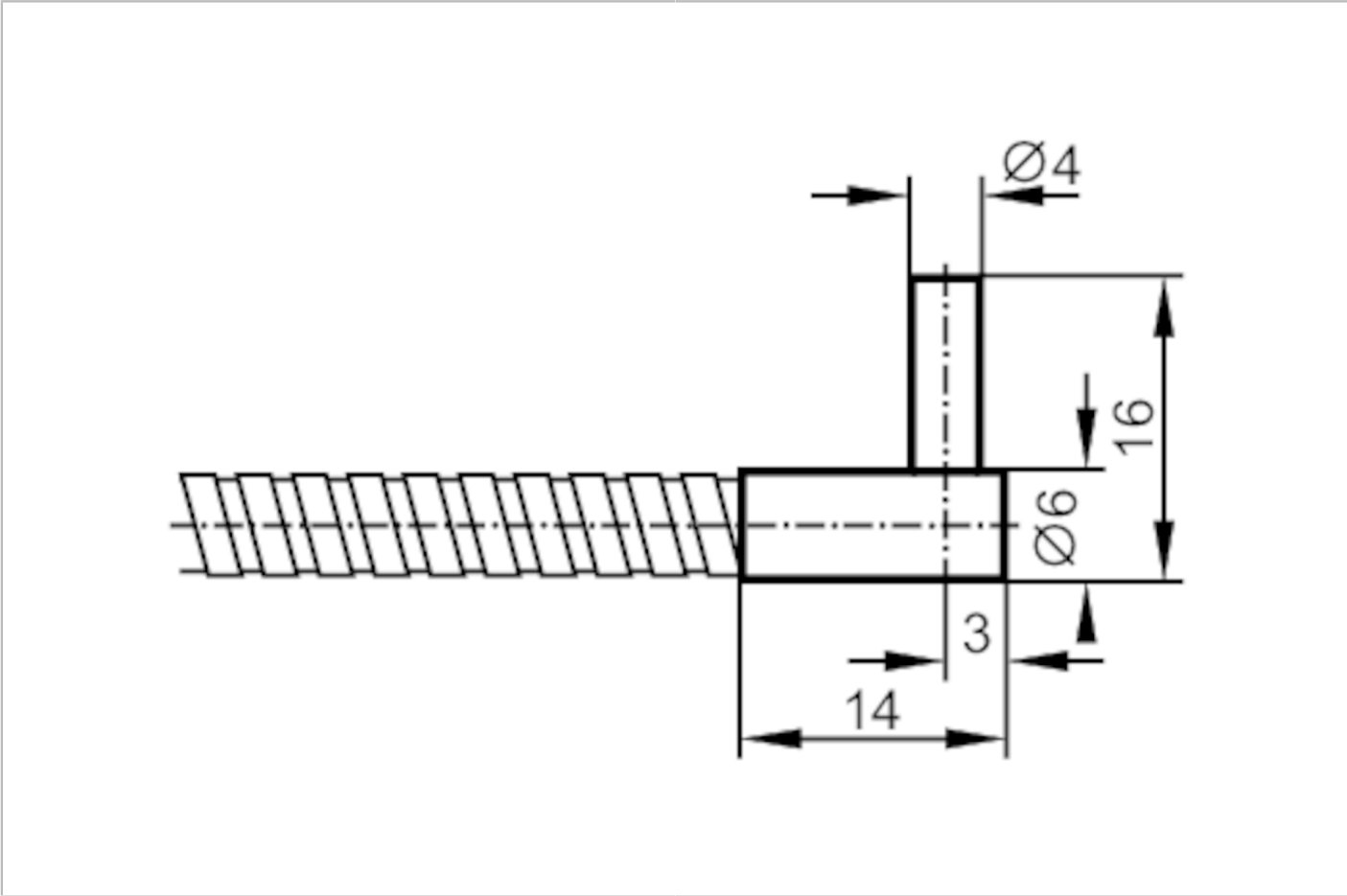

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OGF
OGF		
Range of fiber optics	[mm]	80
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	0.074
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20; (for fixed installation)
Fiber arrangement		●
Material		Adapter: PPE
Fiber material		glass

E20390



Fiber optic through beam sensor

FE-18-A-A-R4

Fiber head material	aluminum
Fiber sheath material	aluminum
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.