




Fiber optic through beam sensor

FE-00-S-V-M4/0,4M

Article no longer available - archive entry

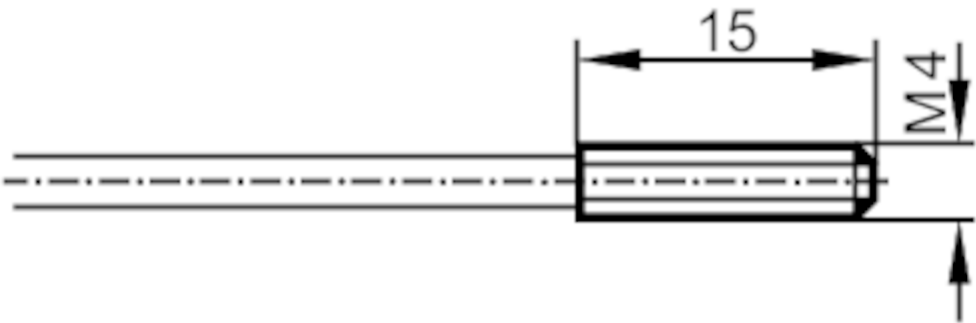

Application		
Function principle		Through-beam sensor
Monitoring range		
Range with fiber optic amplifier type		OKF; OUF
OKF		
Range of fiber optics	[mm]	120
OUF		
Range of fiber optics	[mm]	120
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head thread		M4
Sensing head length	[mm]	15
Total length	[mm]	400
Min. bending radius	[mm]	20
Material		Adapter: ABS
Fiber material		glass

E20394



Fiber optic through beam sensor

FE-00-S-V-M4/0,4M

Fiber head material	stainless steel (1.4305 / 303)
Fiber sheath material	silicone
Remarks	
Pack quantity	1 pcs.