




Fiber optic diffuse reflection sensor

FT-30-A-A-R8/0,3m

Article no longer available - archive entry

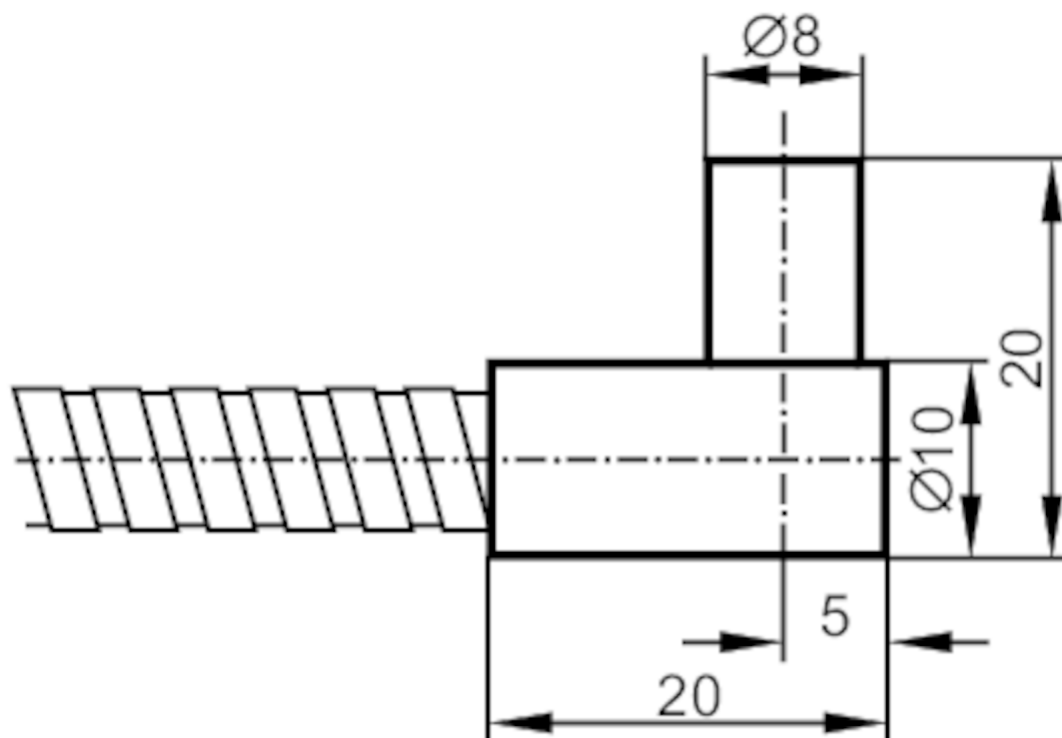

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic
amplifier type

OIF

OIF

Range fiber optics

[mm]

70

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Total length

[mm]

300

Min. bending radius

[mm]

30

Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

Fiber sheath material

aluminum

Remarks

Pack quantity

1 pcs.