




Fiber optic diffuse reflection sensor

FT-30-P-A-M8/1,5M

Article no longer available - archive entry

Alternative articles: E20221

When selecting an alternative article and accessories please note that technical data may differ!

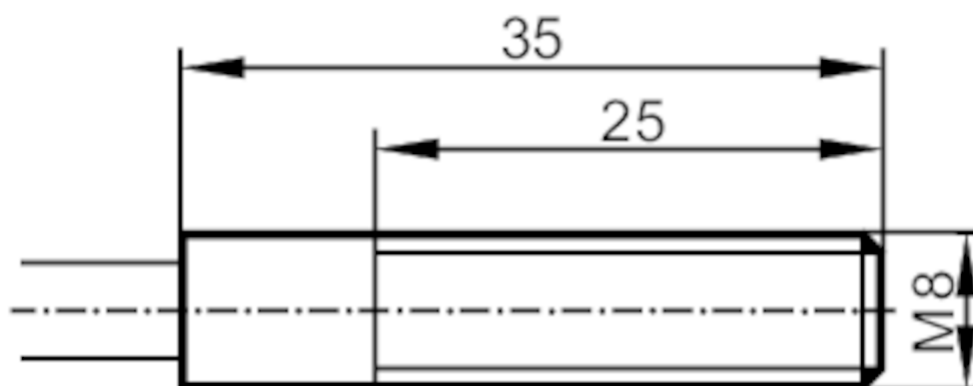

Application

Function principle

Diffuse reflection sensor

Monitoring range

Range with fiber optic amplifier type

OIF

OIF

Range fiber optics [mm]

63

Operating conditions

Ambient temperature [°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M8

Total length [mm]

1500

Min. bending radius [mm]

30

Material

Adapter: PA

Fiber material

glass

Fiber head material

aluminum

E20398



Fiber optic diffuse reflection sensor

FT-30-P-A-M8/1,5M

Fiber sheath material	PVC
Remarks	
Pack quantity	1 pcs.