




## Fiber optic diffuse reflection sensor

FT-11-M-V-M6/3M

Article no longer available - archive entry

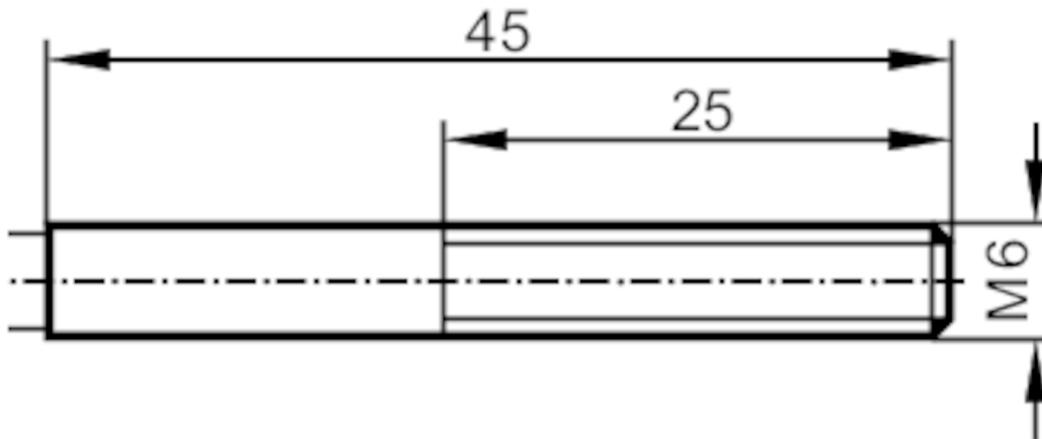

### Application

Function principle Diffuse reflection sensor

### Monitoring range

Range with fiber optic amplifier type OB5030

### OB50

Range fiber optics [mm] 26

### Operating conditions

Ambient temperature [°C] -20...150

### Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	45
Total length [mm]	3000
Min. bending radius [mm]	20
Fiber material	glass
Fiber head material	stainless steel (1.4305 / 303)
Fiber sheath material	metal silicone

# E21039



## Fiber optic diffuse reflection sensor

FT-11-M-V-M6/3M

Remarks	
Pack quantity	1 pcs.