


E21139



Ethernet connection cable

VSTGN040ZDS0005L04STGN040ZDS

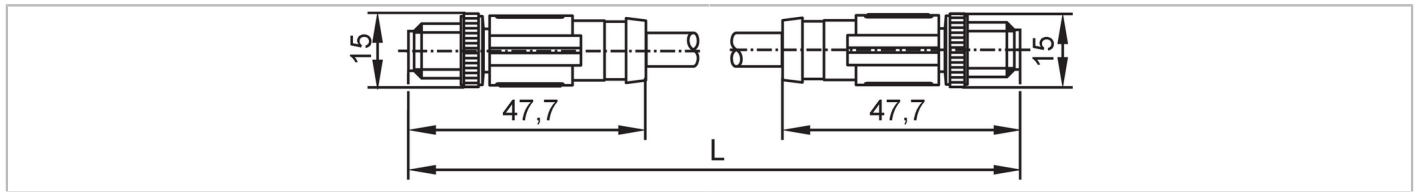

Application	
Special feature	gold-plated contacts; screened cable
Design	Ethernet cable, D-coded
Application	Industrial applications
Electrical data	
Operating voltage [V]	48 AC / 60 DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 65; IP 67
Mechanical data	
Weight [g]	369.2
Molded-body material	TPU (urethane)
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU (urethane), black; Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm; Shielded connection cable: shield connected



Electrical connection

Cable: 5 m, PVC, green, Ø 6.5 mm, screened; PROFINET; 4 x 0.34 mm² (7 x Ø 0.25 mm)

Connection

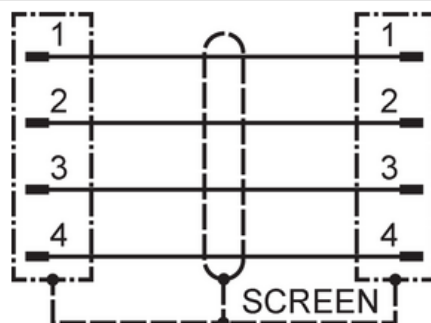

E21139



Ethernet connection cable

VSTGN040ZDS0005L04STGN040ZDS

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Contacts: 4, gold-plated; Moulded body: TPU (urethane), black; Locking: diecast zinc, nickel-plated; Tightening torque: 0.4 Nm; Shielded connection cable: shield connected

