


E21327



Adapter for fiber optics

ADAPTER FOR FIBER OPTICS

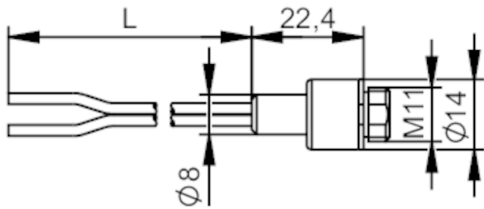

Application

Design for fiber optics M11

Operating conditions

Ambient temperature [°C] -25...60

Mechanical data

Weight [g]	30.9
Total length [mm]	450; (configurable)
Min. bending radius [mm]	30
Fiber arrangement	⊙
Core diameter [mm]	1.0
Outer diameter [mm]	2.2
Material	Adapter: ABS; PPE; POM
Fiber material	PMMA
Fiber sheath material	PE

Accessories

Accessories (optional) Cutter for fibers, E20600

Remarks

Pack quantity 1 pcs.