





Sound tube


SOUND TUBE M30

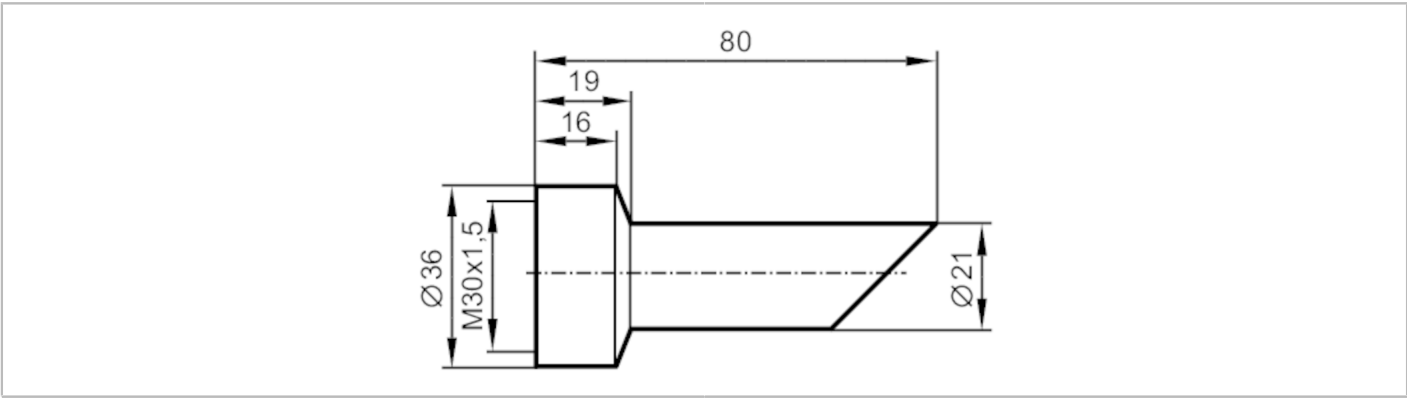


Application	
Design	for all ifm ultrasonic sensors with M30 thread and maximum range of 3.5 m
Mechanical data	
Weight	[g] 24.5
Material	POM
Sealing	Gasket
Remarks	
Pack quantity	1 pcs.
Diagrams and graphs	

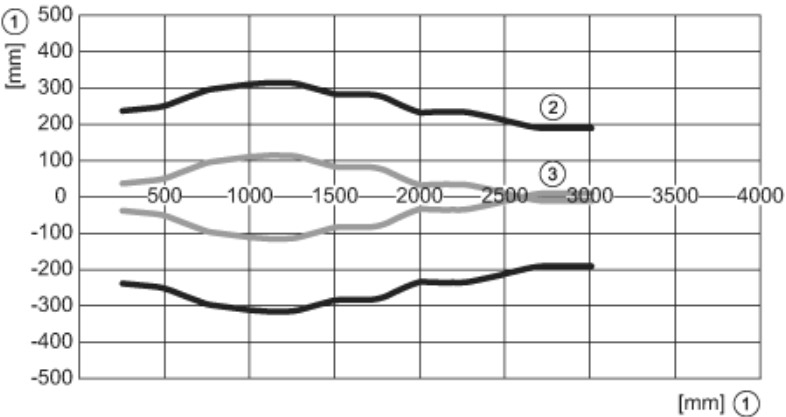


standard sound beam with sound tube

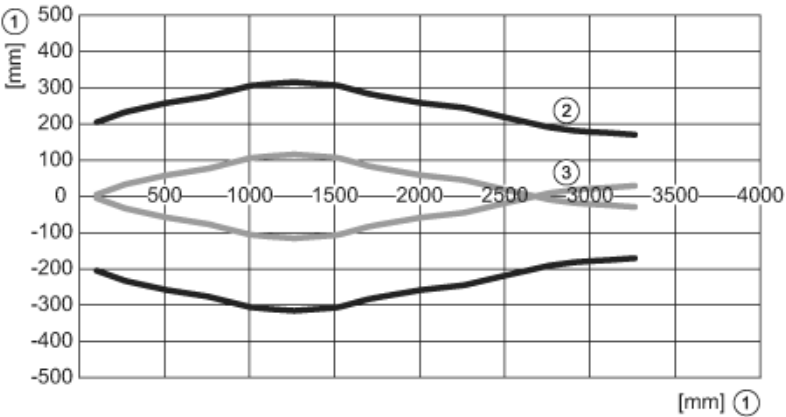

medium sound beam with sound tube

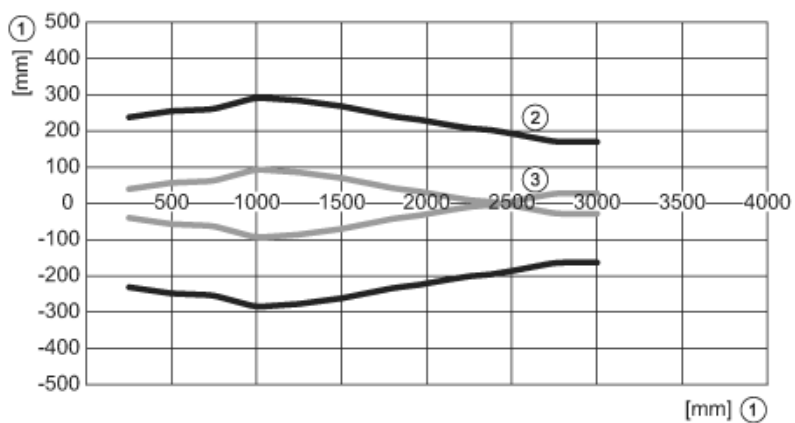

narrow sound beam with sound tube

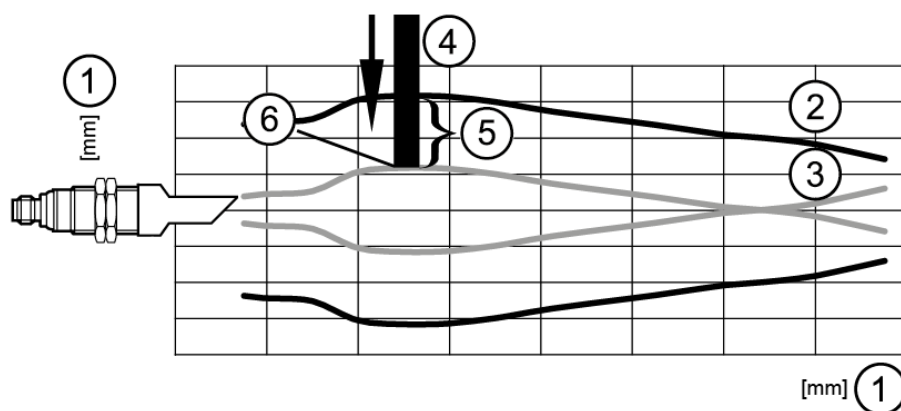

- 1 Distance
- 2 Monitoring range
- 3 switch-on/switch-off graph
- 4 Target
- 5 50 % of the target in the detection zone
- 6 Set point