


E2M202



Adapter cables for cameras with video output

CONNECTION CABLE M16 3M

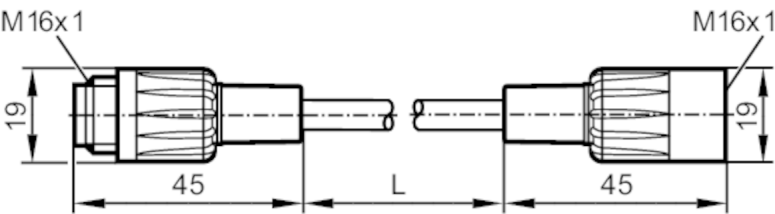

Application

System	Free from silicone; gold-plated contacts
Design	camera with video output O2M20x
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-45...85
Protection		IP 67

Mechanical data

Weight	[g]	191.9
Material		housing: PVC; sealing: EPDM
Material nut		PVC

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 3 m, PVC, black, Ø 6 mm; 3 x 0.34 mm² / AWG 22 + 1 x 0.11 mm² / AWG 26

Electrical connection - plug

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm






Adapter cables for cameras with video output

CONNECTION CABLE M16 3M

Electrical connection

Connection

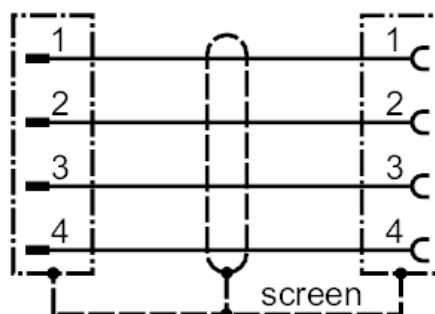

Electrical connection - Socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

