


E2M204



Adapter cables for cameras with video output

CONNECTION CABLE M16 11M

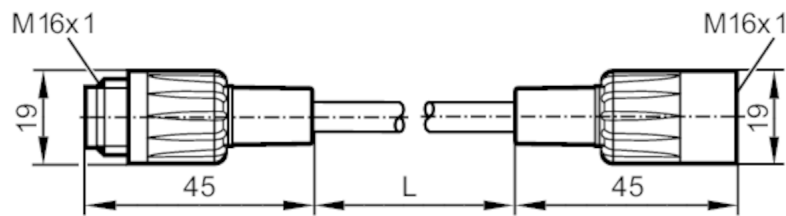

Application		
System		Free from silicone; gold-plated contacts
Design		camera with video output O2M20x
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 DC
Protection class		II
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-45...85
Protection		IP 67
Mechanical data		
Weight	[g]	589.5
Material		housing: PVC; sealing: EPDM
Material nut		PVC
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 11 m, PVC, black, Ø 6 mm; 3 x 0.34 mm ² / AWG 22 + 1 x 0.11 mm ² / AWG 26		
Electrical connection - plug		
Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm		






Adapter cables for cameras with video output

CONNECTION CABLE M16 11M

Electrical connection

Connection

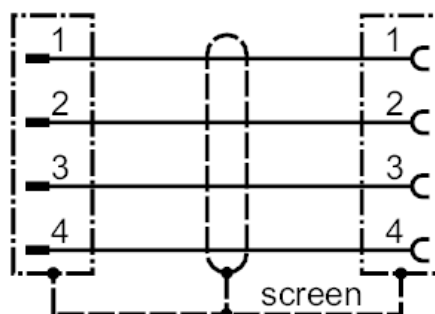

Electrical connection - Socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

