


E2D100



USB-cable connection

ADAPTER CABLE M8 RS485-USB

Article no longer available - archive entry

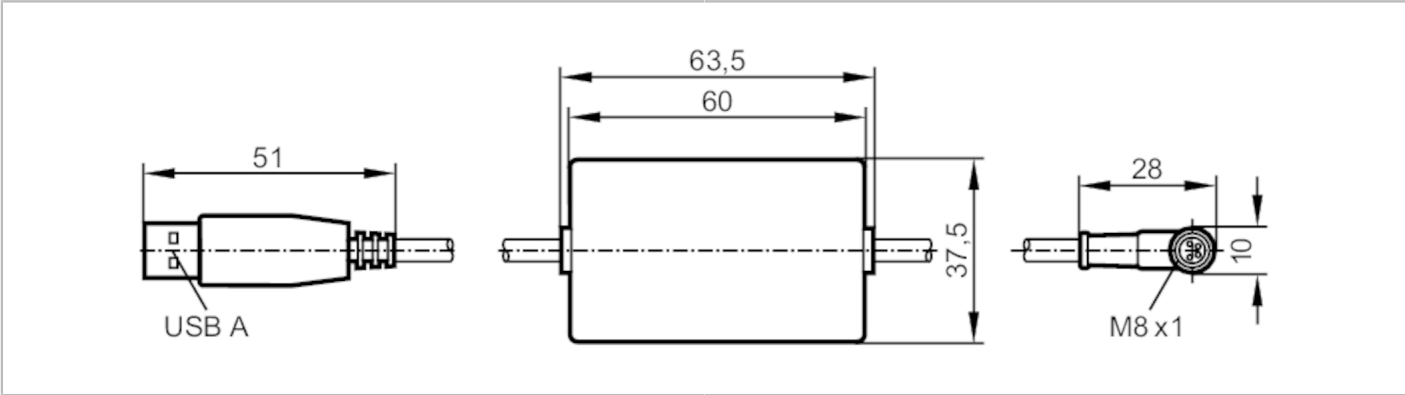

Application		
System	Halogen-free	
Electrical data		
Protection class	III	
Operating conditions		
Ambient temperature	[°C]	0...60
Protection	IP 54	
Tests / approvals		
EMC	EN 61000-6-1	
Mechanical data		
Material	PUR	
Molded-body material	PUR	
Material nut	brass, nickel-plated	
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 2 m, PUR, Halogen-free; 4 x 0.25 mm²		
Electrical connection - Stecker		






USB-cable connection

ADAPTER CABLE M8 RS485-USB


Connection

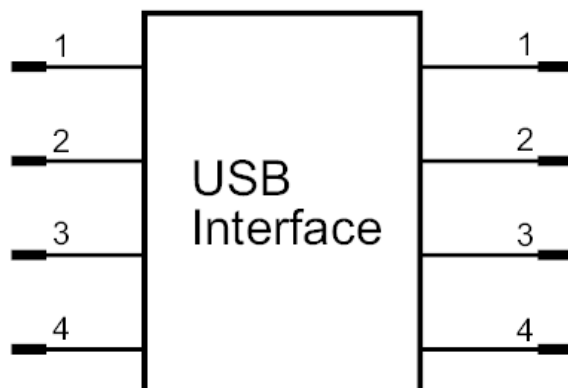

Electrical connection - plug

Connector: 1 x USB, straight; Moulded body: PUR; Locking: brass, nickel-plated

 Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated



Connection

