


E30436



Patchcords with valve plug

PLUG M12 - DIN VALVE FORM A

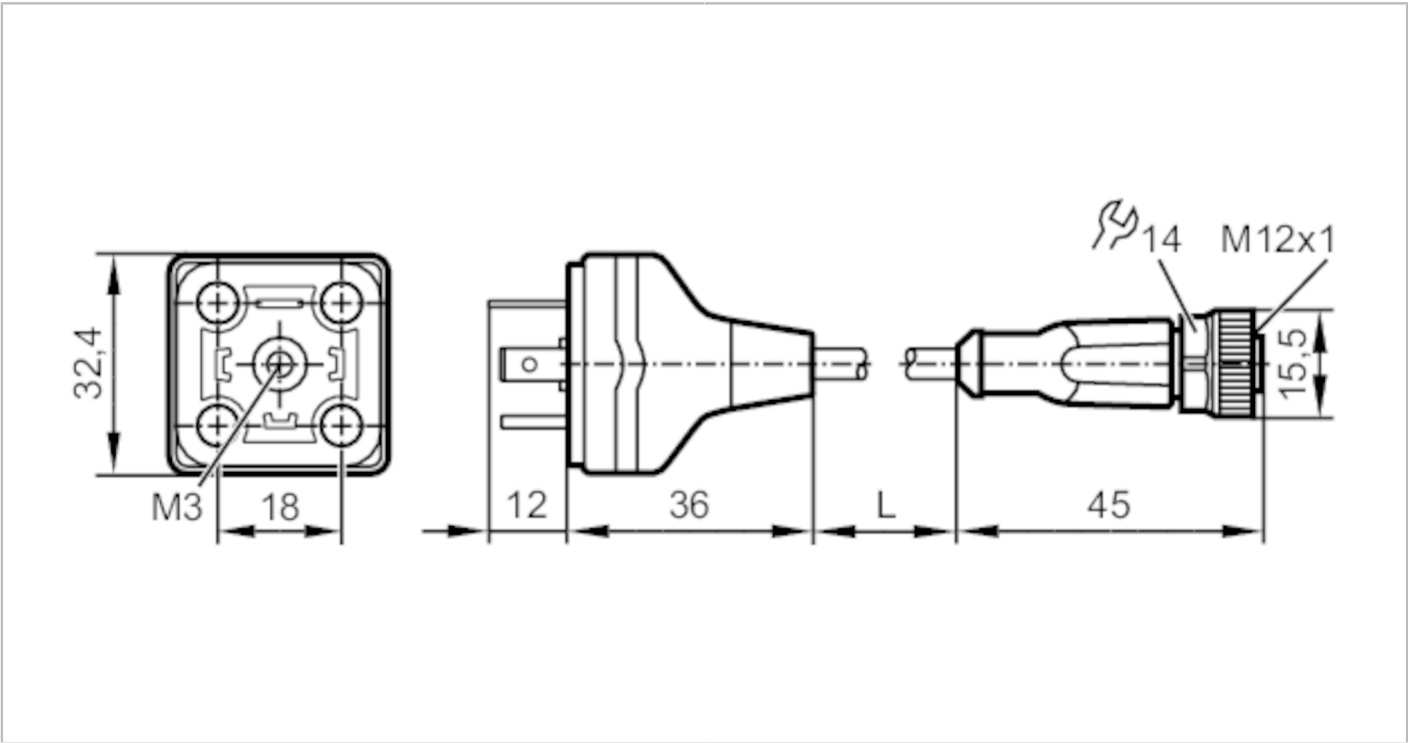

| Application | | |
|-------------------------|------|----------------------------------|
| System | | Free from silicone; Halogen-free |
| Free from silicone | | yes |
| Electrical data | | |
| Operating voltage | [V] | < 50 AC / < 60 DC |
| Max. current load total | [A] | 4 |
| Operating conditions | | |
| Ambient temperature | [°C] | -25...85 |
| Protection | | IP 65 |
| Mechanical data | | |
| Weight | [g] | 66.7 |
| Molded-body material | | TPU (urethane) |
| Material nut | | brass, nickel-plated |
| Sealing material | | FKM |
| Remarks | | |
| Pack quantity | | 1 pcs. |

E30436




Patchcords with valve plug

PLUG M12 - DIN VALVE FORM A

Electrical connection - plug


Connector: 1 x valve type A DIN, straight; Moulded body: TPU (urethane), black; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

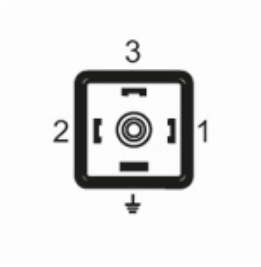

Electrical connection

Cable: 0.4 m, PUR, Halogen-free, black, Ø 5.5 mm; 5 x 0.50 mm²

Connection

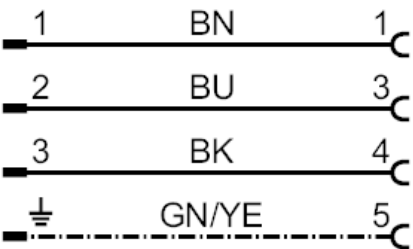

Core colors :
BK = black
BN = brown
BU = blue
GN/YE = green/yellow

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), black; Locking: brass, nickel-plated; sealing: FKM; Tightening torque: 0.6...1.5 Nm

