




Welding adapter for process sensors

WELDING ADAPT D85 G1 V4A 3A

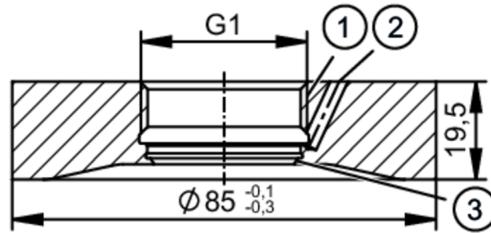

- 1 G1 Internal thread Aseptoflex Vario
- 2 Leakage port
- 3 sealing area



CE EHEDG Certified

Application

Design	with leakage port (3A)
Installation	for thin wall thicknesses
Pressure rating [bar]	16
Note on pressure rating	for the connection sensor - adapter

Tests / approvals

Pressure equipment directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]	762.6
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / R
Sensor connection	G 1 Internal thread Aseptoflex Vario
Process connection	Welding adapter Ø 85 mm
Sealing	Gasket

Accessories

Items supplied	O-ring: 1 x 24 x 2, EPDM, E30054
Accessories (optional)	O-ring: 1 x 24 x 2, FKM, E30123

Remarks

Pack quantity	1 pcs.
---------------	--------