


E30512



O-ring

O-RG 16,40x1,00/FFKM

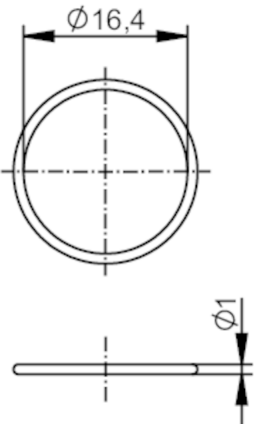

Operating conditions		
Ambient temperature	[°C]	-5...200
Mechanical data		
Weight	[g]	1.5
Inside diameter	[mm]	16.4
Outer diameter	[mm]	18.4
Material		FFKM
Remarks		
Pack quantity		1 pcs.