


E30019



Wirable plug

SSTGH040VASFPKG

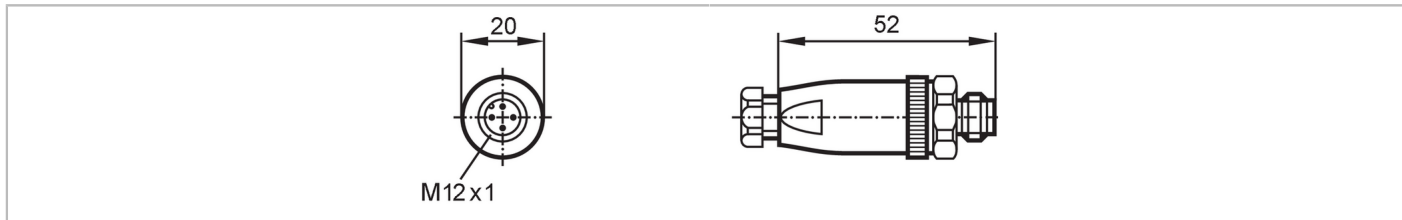

Application

Special feature	gold-plated contacts
Application	Industrial applications

Electrical data

Operating voltage	[V]	10...55 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	23
Dimensions	[mm]	20 x 20 x 52
Molded-body material		PA
Material nut		stainless steel (1.4571/316Ti)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: stainless steel (1.4571/316Ti)



Connection

