


# E30019



## Wirable plug

SSTGH040VASFPKG

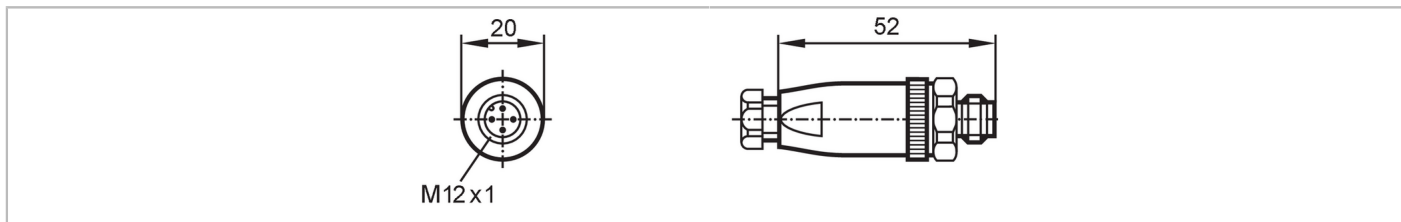

### Application

Special feature	gold-plated contacts
-----------------	----------------------

### Electrical data

Operating voltage [V]	10...55 DC
Max. current load total [A]	4; (...40 °C)

### Operating conditions

Ambient temperature [°C]	-40...85
Protection	IP 67

### Mechanical data

Weight [g]	23
Dimensions [mm]	20 x 20 x 52
Molded-body material	PA
Material nut	stainless steel (1.4571/316Ti)

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: stainless steel (1.4571/316Ti)



### Connection

