




## Process adapter pipe fitting DIN 11864

ADAPT IFM-DIN11864-1A/DN50

Article no longer available - archive entry

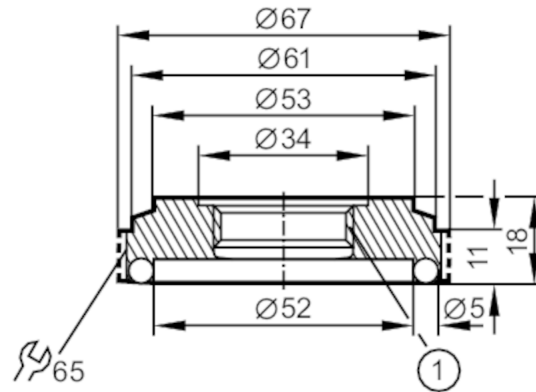

1 Aseptoflex thread

EC 1935/2004 

## Application

Pressure rating	[bar]	25
-----------------	-------	----

## Tests / approvals

Pressure equipment directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

## Mechanical data

Weight	[g]	328.4
Material		stainless steel (1.4404 / 316L)
Sensor connection		Aseptoflex
Process connection		Pipe fitting DN50 DIN 11864-1-A-BS
Surface characteristics Ra/Rz of the wetted parts		0.4 / 4
Hygienic equipment class to DIN 11866		H4

## Remarks

Pack quantity	1 pcs.
---------------	--------