




Welding thermowell for temperature sensors

THERMOWELL,D6/WELD-IN/G1/2 conical/L=150

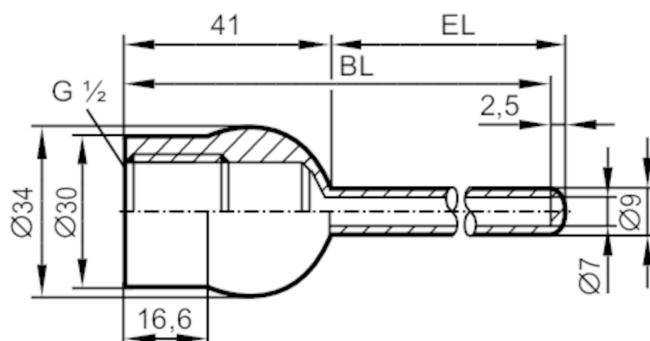

EC 1935/2004 EHEDG Certified



Application		
Design		for temperature sensors EL = 150 mm
Pressure rating	[bar]	300
Mechanical data		
Weight	[g]	184.7
Material		stainless steel (1.4404 / 316L)
Sensor connection		G 1/2 sealing cone Ø 6 mm
Process connection		Welding adapter Ø 34 mm
Surface characteristics Ra/Rz of the wetted parts		≤ 0.6 / -
Installation length EL	[mm]	149
Bore length BL	[mm]	187
Remarks		
Pack quantity		1 pcs.