 



E38795



Thermowell for temperature sensors

THERMOWELL, D3/DIN10/15/20 CLAMP/EL=38

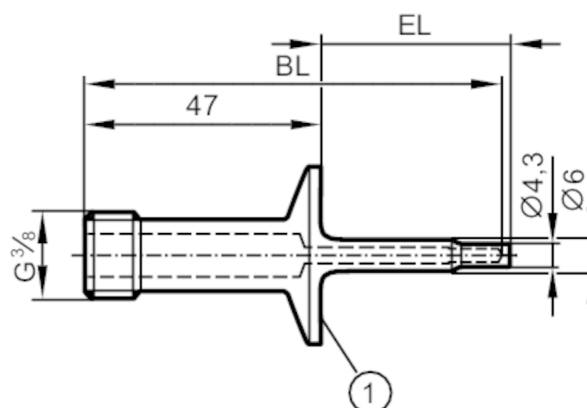

Application	
Design	for temperature sensors EL = 83 mm
Pressure rating [bar]	25
Mechanical data	
Weight [g]	70
Material	stainless steel (1.4435 / 316L)
Sensor connection	G 3/8 Internal thread Ø 3 mm
Process connection	Clamp DN10...DN20 (1/2...3/4") DIN 32676 (ISO 2852)
Surface characteristics Ra/Rz of the wetted parts	< 0.4 / -
Installation length EL [mm]	38
Bore length BL [mm]	83
Remarks	
Pack quantity	1 pcs.