




Thermowell for temperature sensors

THERMOWELL, D3/1-1,5"CLAMP/EL=50

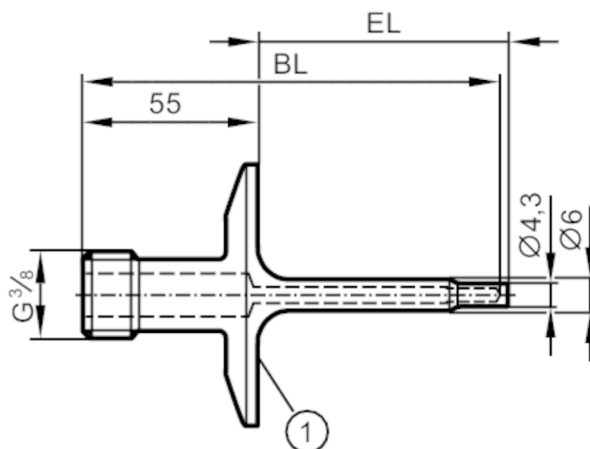

EC 1935/2004 FDA

Application

Design	for temperature sensors EL = 83 mm
Pressure rating [bar]	25

Mechanical data

Weight [g]	108.4
Material	stainless steel (1.4435 / 316L)
Sensor connection	G 3/8 Internal thread Ø 3 mm
Process connection	Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)
Surface characteristics Ra/Rz of the wetted parts	< 0.4 / -
Installation length EL [mm]	50
Bore length BL [mm]	83

Remarks

Pack quantity	1 pcs.
---------------	--------