



Female cordset

ADOGH050MSS0010E05

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 10 m, PVC, orange; 5 x 0.34 mm² (42 x Ø 0.1 mm)		

Electrical connection - Socket		
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated		

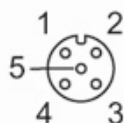


E40051



Female cordset

ADOGH050MSS0010E05

Connection

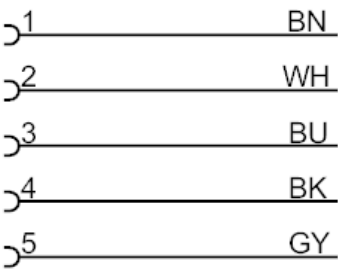

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white