

# E40075




## Female cordset

ADOAH050MSN0002A05

Article no longer available - archive entry

Alternative articles: ENC10A

When selecting an alternative article and accessories please note that technical data may differ!

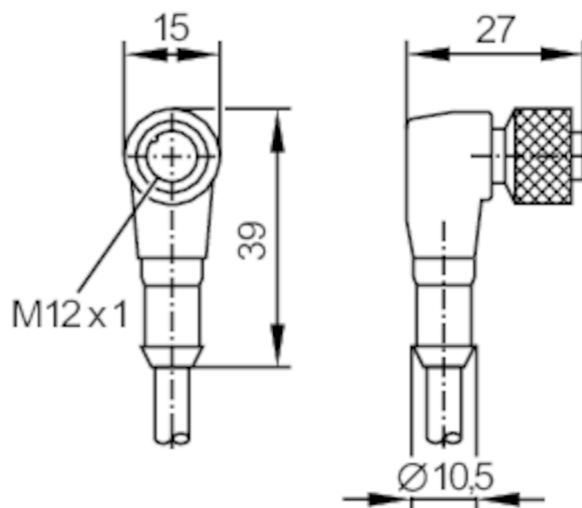

### Application

Application Ex zone 1

### Electrical data

Operating voltage [V] 10...30 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Safety classification

Max. internal capacitance [nF] 0.152

Max. internal inductance [μH] 1.2

### Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane)

Molded-body material TPU (urethane)

Material nut brass, nickel-plated

### Remarks

Remarks When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.  
The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity 1 pcs.

# E40075



## Female cordset


ADOAH050MSN0002A05

### Electrical connection

Cable: 2 m, PUR / PVC, blue, Ø 6 mm; 5 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

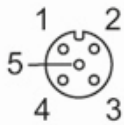

### Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white