


E40212



Teach button for flow sensors

SC TEACH BUTTON OR

Article no longer available - archive entry

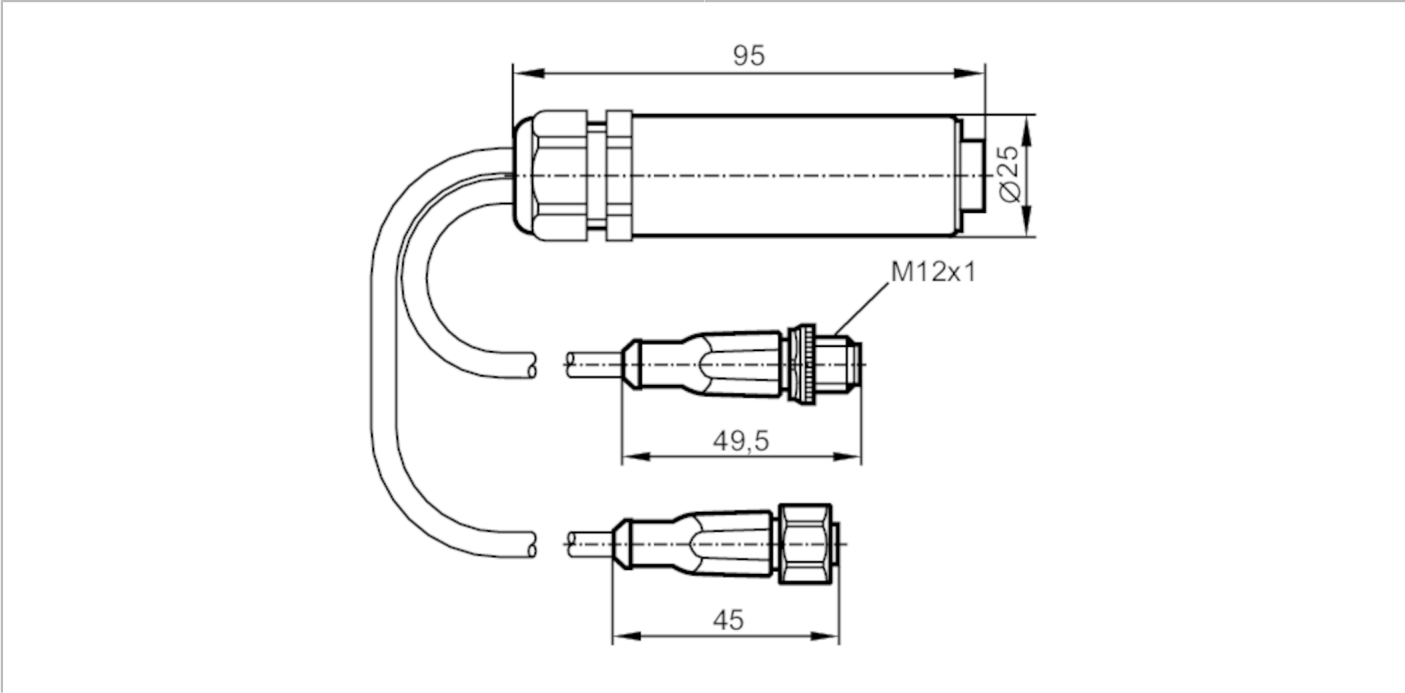

Application		
Design		for flow sensors SC with relay output as normally open
Electrical data		
Frequency AC	[Hz]	47...63
Operating voltage tolerance	[%]	15
Operating voltage	[V]	< 24 AC/DC; (to SELV/PELV)
Operating conditions		
Protection		IP 40
Mechanical data		
Weight	[g]	225.5
Material		stainless steel (1.4305 / 303); PA; PMMA
Remarks		
Notes		Article to be discontinued
Pack quantity		1 pcs.

E40212




Teach button for flow sensors

SC TEACH BUTTON OR

Electrical connection

Cable: 0.9 m, PUR

Connection

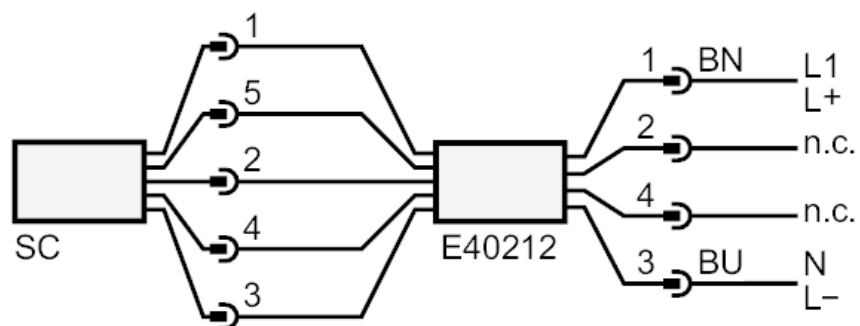

BN =

BU =

Core colors :

brown

blue