


E43004



Clamp fitting for process sensors

MOUNTING ADAPTER G1

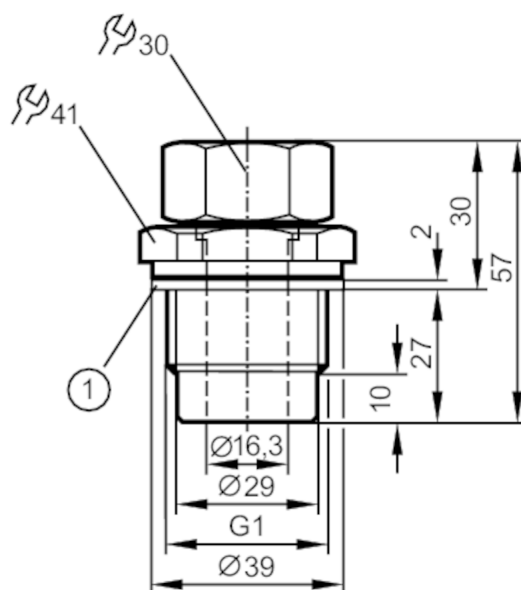

1 sealings

Application

Design	for capacitive level sensors LK, LI, LT, LL
Installation	Clamp fitting
Pressure rating [bar]	0.5

Operating conditions

Ambient temperature [°C]	0...80
--------------------------	--------

Mechanical data

Weight [g]	335
Dimensions [mm]	Ø 39 / L = 57
Material	flange: stainless steel; knurled nut: stainless steel; Spacer: brass; clamping ring: FKM; sealing: Tesnit
Tightening torque [Nm]	6...9
Sensor connection	Ø 16 mm
Process connection	threaded connection G 1 external thread

Remarks

Pack quantity	1 pcs.
---------------	--------