




Coaxial tube for level sensors

LR COAX TUBE G3/4 L1000/2BORES

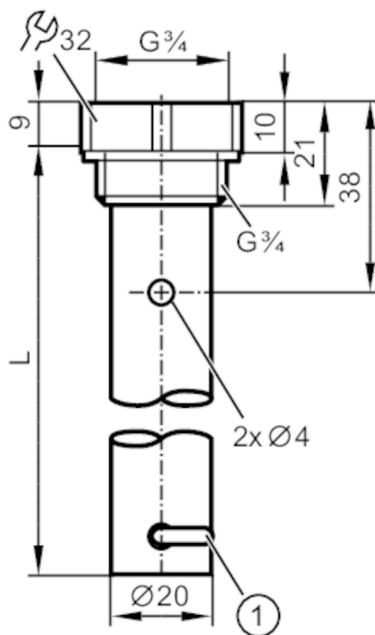

1 Fixing bracket for centring piece

Application

Design	Version without holes, for level sensors, LR
Medium temperature [°C]	-40...200
Pressure rating [bar]	16
Vacuum resistance [mbar]	-1000

Mechanical data

Weight [g]	600
Material	Coaxial tubes for level sensors: stainless steel (1.4301 / 304); sealing: NBR fiber-reinforced; centring piece: PPS fiber-reinforced; fixing bracket: stainless steel (1.4310 / 301)
Sensor connection	threaded connection G 3/4 Internal thread
Process connection	threaded connection G 3/4 external thread
Length L [mm]	1000

Accessories

Items supplied	sealing: 1
Accessories (optional)	Centering piece for coaxial tubes: 1, E43222

Remarks

Pack quantity	1 pcs.
---------------	--------