


E60122



Female wirable connectors

SDOGK120MKRFGSG

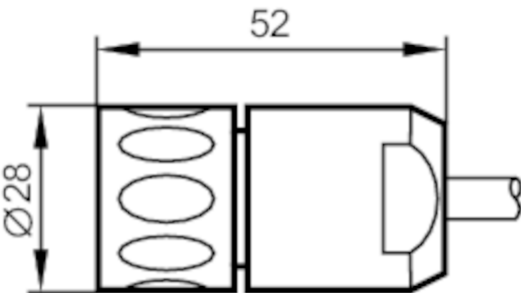

Electrical data

Operating voltage	[V]	4.5...30 DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-40...125
Protection		IP 67

Mechanical data

Weight	[g]	43
Dimensions	[mm]	28 x 28 x 52
Material		brass plastic coated; PA 6.6 black
Molded-body material		brass / PA 6.6, plastic coated
Material nut		brass, plastic coated / PA 6.6, plastic coated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

soldering: ...1 mm²

Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: brass, plastic coated
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: PA 6.6, plastic coated

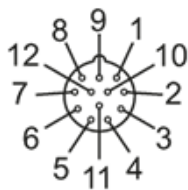

E60122



Female wirable connectors

SDOGK120MKRFKSG

Connection

