


E60123



Wirable plug


SSTGK120MKRFKSG

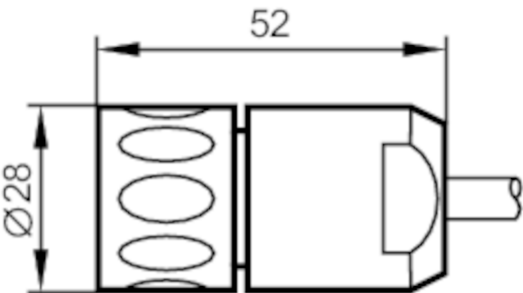

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	44.8
Dimensions	[mm]	28 x 28 x 52
Material		brass plastic coated; PA 6.6 black
Molded-body material		brass / PA 6.6, plastic coated
Material nut		brass, plastic coated / PA 6.6, plastic coated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
soldering: ...1 mm²	

Electrical connection - plug	
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: brass, plastic coated	
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: PA 6.6, plastic coated	

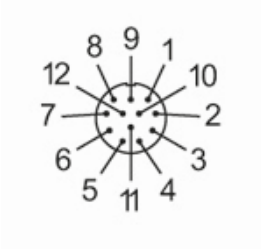

E60123



Wirable plug

SSTGK120MKRFGSG

Connection

