


# E60124



## Female wirable connectors

SDOGK120--LFKSG

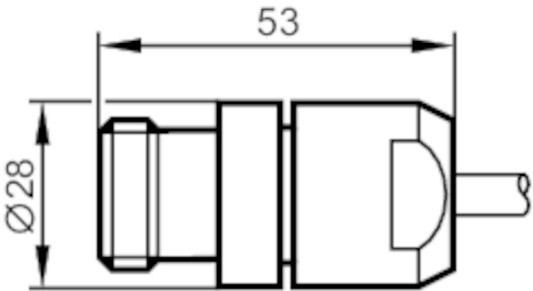


Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	45
Dimensions	[mm]	28 x 28 x 53
Material		brass plastic coated; PA 6.6 black
Molded-body material		brass / PA 6.6, plastic coated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
soldering: ...1 mm²	

Electrical connection - Socket	
--------------------------------	--

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated

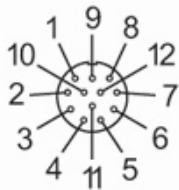

# E60124



## Female wirable connectors

SDOGK120--LFKSG

### Connection

