


E60136



Female wirable connectors

SDOGK120MKRFGSG

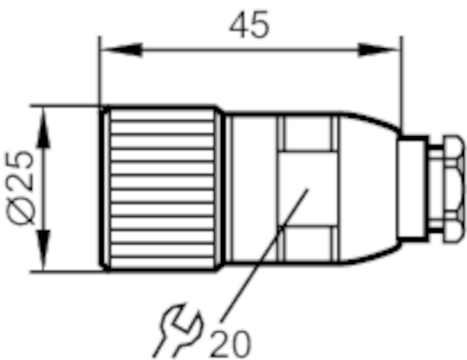

Electrical data

Operating voltage [V] 4.5...30 DC

Operating conditions

Ambient temperature [°C] -40...125

Protection IP 67

Mechanical data

Weight [g] 79

Dimensions [mm] 25 x 25 x 45

Material brass nickel-plated

Molded-body material brass, nickel-plated

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection

soldering: ...1 mm²; Cable sheath: Ø 4.5...6 mm

Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated



E60136



Female wirable connectors

SDOGK120MKRFKSG

Connection

