


E60144



Female cordset

ADOGK120MKR0005B12

Article no longer available - archive entry

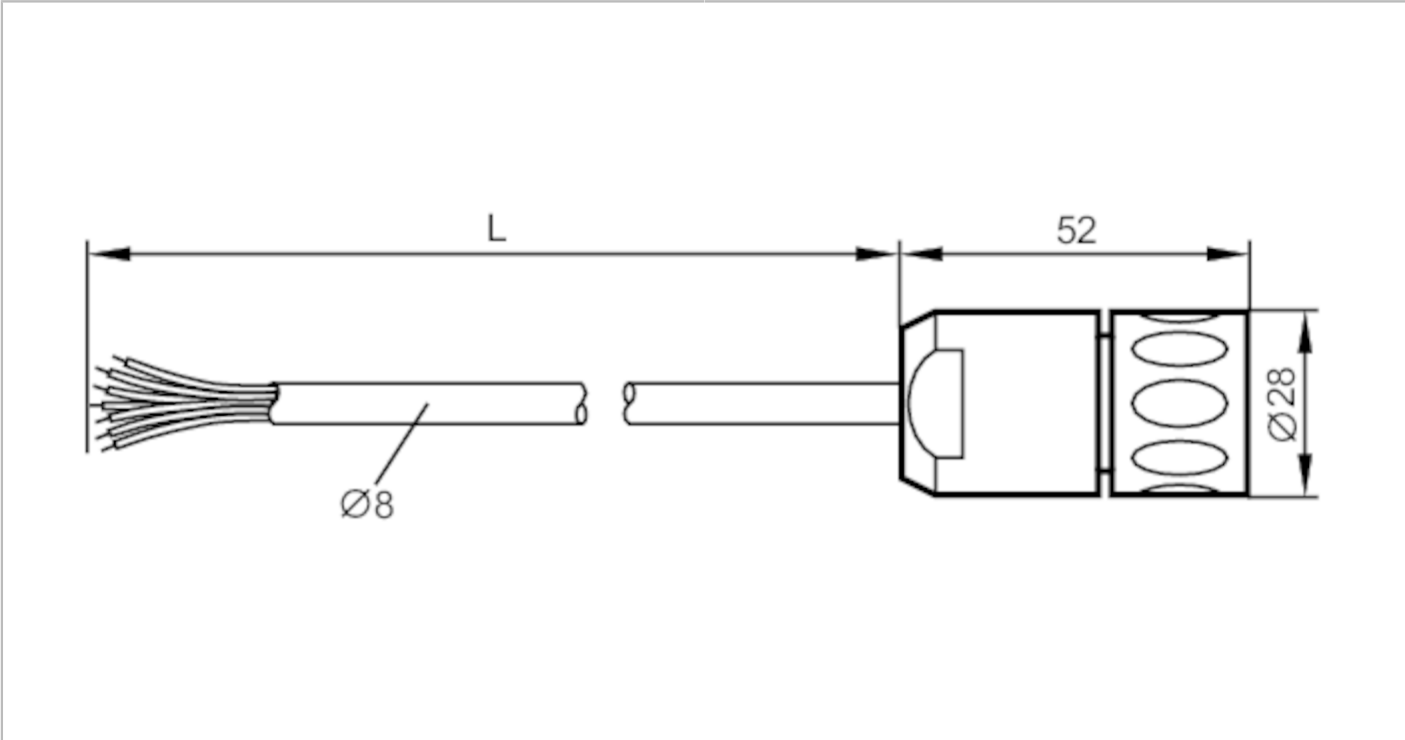

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Weight	[g]	507.6
Dimensions	[mm]	28 x 28 x 52
Material		brass plastic coated; PA 6.6 black
Molded-body material		brass / PA 6.6, plastic coated
Material nut		brass, plastic coated / PA 6.6, plastic coated
Remarks		
Pack quantity		1 pcs.

E60144



Female cordset

ADOGK120MKR0005B12


Electrical connection

Cable: 5 m, PUR, Ø 8 mm; 8 x 0.14 mm² + 4 x 0.5 mm²

Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: brass, plastic coated

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: PA 6.6, plastic coated

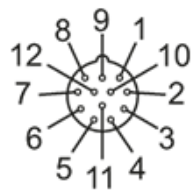

Connection

1	PK
2	BU
3	RD
4	BK
5	BN
6	GN
7	VT
8	GY
9	n.c.
10	WH/GN
11	WH
12	BN/GN

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white