


E60146



Female wirable connectors

SDOGK210MKRFGSG

Article no longer available - archive entry

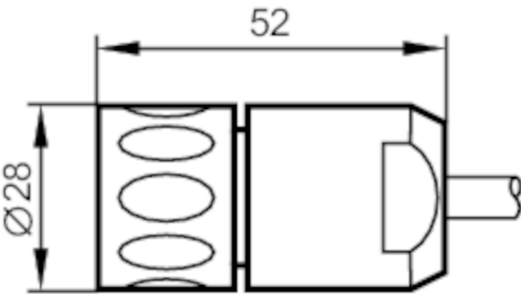

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	68.8
Dimensions	[mm]	28 x 28 x 52
Material		brass plastic coated; PA 6.6 black
Molded-body material		brass / PA 6.6, plastic coated
Material nut		brass, plastic coated / PA 6.6, plastic coated
Remarks		
Pack quantity		1 pcs.

E60146



Female wirable connectors

SDOGK210MKRFGSG


Electrical connection

Soldering/crimping connection: ...0.5 mm²

Electrical connection - Socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: brass, plastic coated

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, plastic coated; Locking: PA 6.6, plastic coated

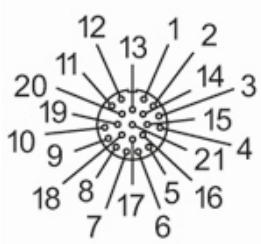

Connection

- 1 _____
- 2 _____
- 3 _____
- 4 _____
- 5 _____
- 6 _____
- 7 _____
- 8 _____
- 9 _____
- 10 _____
- 11 _____
- 12 _____
- 13 _____
- 14 _____
- 15 _____
- 16 _____
- 17 _____
- 18 _____
- 19 _____
- 20 _____
- 21 _____